

Spot Cooling



Extend the Life
of Your Equipment

Complete Kit	OD1232-SPOT / DIN Part Number - 124141794 Includes: 120x32mm Fan * DIN rail DIN mount fan bracket Mounting screws 2 fan guards Power adaptor with 6' cord Automotive grade, double-sided, mount anywhere tape
Spot Cooler Only	OD1232-SPOT Part Number - 124141794 Includes: 120x32mm Fan * 1 fan guard Power adaptor with 6' cord
Fan ID	OD1232-12HB-03 *
VOLTAGE INPUT	120VAC / 60Hz
INPUT POWER	19 Watts
DC Nominal Current	0.60 A
DC Locked Current	0.05 A
Rated Speed (RPM)	3750 Max. (40C)
Airflow	65CFM @ 25C / 120CFM @ 40C
Noise Level (dB)	20 ~ 47
Max. Static Pressure	0.43" H ₂ O
Bearing System	Dual Ball
Frame & Impeller	PBT, UL94V-O plastic
Motor	Brushless DC, auto restart, polarity protected. Thermal Control.
Bearing System	Dual ball bearing
Insulation Resistance	10M ohm between leadwire and frame (500VDC)
Dielectric Strength	5mA max at 1500VAC for 1 minute between the leadwire and frame
Operation Temperature	-10C ~ +70C
Life (L10)	60,000 hours

Patent Pending

Thermal Speed Control
Airflow Range

65 CFM at 25C
120 CFM at 40C

Energy Saving Solution for your
Green Initiative

*Clips to standard
DIN rail*




*Plugs into any
115VAC power
source*

OD1232-SPOT / DIN

Part Number - 124141794
120x32mm
Thermally controlled Fan *
6' Cord with adaptor
2 guards (1 installed)
DIN rail
DIN mount fan bracket
Mounting screws
Automotive grade, double-sided,
mount anywhere tape

OD1232-SPOT

Part Number - 124141794
120x32mm
Thermally controlled Fan *
6' Cord with adaptor
1 guard installed

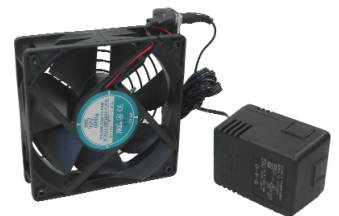

OD9225-SPOT - Instant smart cooling
for small spaces is also available in a
smaller package

Part Number - 193141791
92x25mm thermally controlled fan.
[50CFM (3100RPM) at 34C to
< 30CFM (1600RPM) at 22C]
6' cord with adaptor
1 guard installed



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Orion Fans:

[OD1232-SPOT](#) [OD1232-SPOT/DIN](#)