


720 Series

Electromechanical Hour Meter

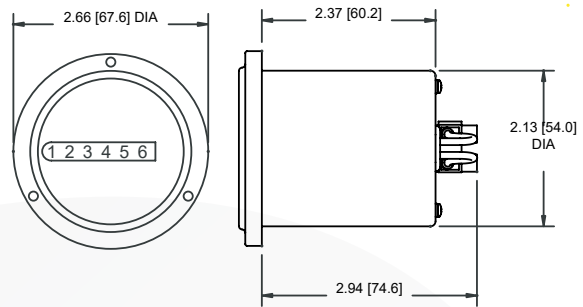

Panel cutout: 2.16" [54.9] Dia.
Mounting holes: 0.125" [3.2] Dia. on 2.44" [62.0] B.C.

6 figure (non-reset), AC hour meter encased in a rugged steel housing. The faces of these meters are sealed for periodic washdowns.

Key Features

- Rugged steel housing
- Options include:
 - Readouts to 9999.99 hrs.
 - Gasket (721-0004)

Applications

- Control panel
- Industrial equipment
- Test equipment

Specification

Figures: 6 figure (non-reset), 0.19" [5mm] high, 99,999.9 (non-reset)
Reset: Non-reset
Voltages: 115VAC (+/- 10%), 60Hz.
Power: 3 watts max.

Mounting: Panel (3-hole)
Termination: 6" [152mm] wire leads
Temp. Range: -40°F to +160°F [-40°C to +70°C]
Approvals: UL Recognized, CE Compliant, ROHS
Weight: 10 oz. [284g]

Part Numbers

720-0007 115VAC/60Hz, non-reset, 3-hole round, 6" [152.4mm] wire leads



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Trumeter:](#)

[720-0007](#)