

94 Series

LCD Electronic Totalizer



A 6 figure, battery powered, push-button or key reset, electronic counter, available in base mount or panel mount configuration. No external power supply is required. Large 0.50" [12mm] LCD figures for fast, easy reading. Operates at 6-240 VAC or VDC. Long lasting internal lithium battery. Attractive styling and silent operation make these models equally well-suited for lab or office equipment applications.

Key Features

- No external power supply needed
- Long life lithium battery
- Large easy reading display
- Operates at 6 to 240 VAC or VDC

Applications


- Office equipment
- Production
- Test Labs
- Control Panels

Specification

Figures	6 LCD figures, 0.50" [12mm] high
Reset	Push-button, or lock and key
Speed	0-40 counts/second, (min. 12.5ms - on, 12.5ms - off)
Input	6-240VAC or VDC
Mount	Base or panel
Terminations	(2) #22 AWG 221°F [105° C] wire leads, 8" [203mm] long
Power Source	Internal lithium battery
Temp. Range	-14°F to +122°F [-26°C to +50°C]
Weight	18 oz. [510g]


Dimensions

Base Mount

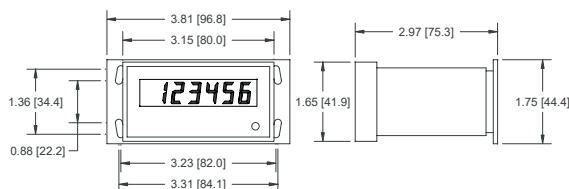


Mounting holes: 0.14" x 0.24" [3.6mm x 6.1mm] slots

Panel Mount

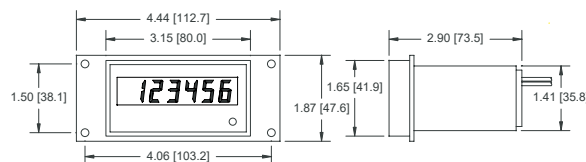

Panel cutout: 3.0" x 1.75" [76.2mm x 44.5mm]
Mounting holes: 0.17" [4.3mm] Dia.

Panel Mount/Lock & Key Reset

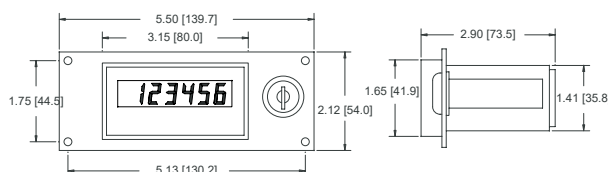

Panel cutout: 4.75" x 1.50" [76.2mm x 44.5mm]
Mounting holes: 0.17" [4.3mm] Dia.

Part Numbers

9415-001	6 figure, base mount, push-button reset
9415-003	6 figure, panel mount, push-button reset
9415-005	6 figure, panel mount, lock and key reset

Note: Load resistor (1500 ohms 10 watts) across input terminals required when using AC sensors



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Trumeter:

[1071-035](#) [9415-001](#) [9415-003](#) [9415-005](#)