


Captive Screw Type 2 6-32 Thread

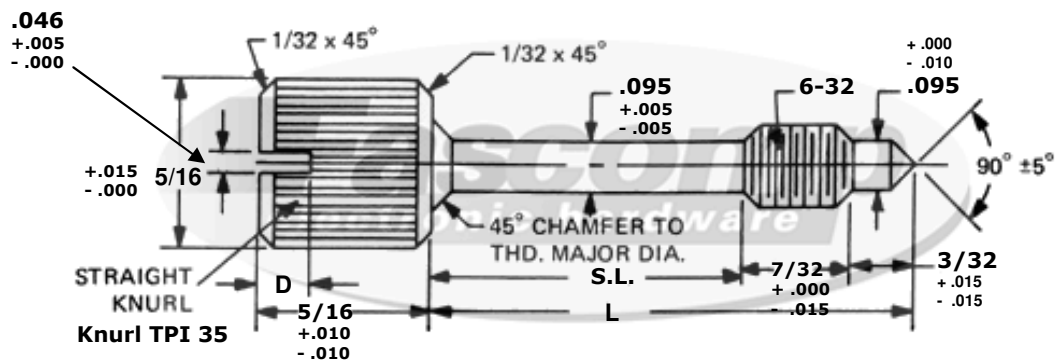

Create a part number:

Length	Material	Finish
FCXXXX	XX	XX

Captive Screws - 6-32 Thread				
✓ FCXXXX	Length (L)	S.L. +.010 -.010	D. +.010 -.000	
FC0389	7/16	1/8	.078	
FC0390	1/2	3/16	.078	
FC0391	9/16	1/4	.078	
FC0392	5/8	5/16	.078	
FC0393	11/16	3/8	.078	
FC0394	3/4	7/16	.078	
FC0395	13/16	1/2	.078	
FC0396	7/8	9/16	.078	
FC0397	15/16	5/8	.078	
FC0398	1	11/16	.078	
FC0399	1-1/16	3/4	.078	
FC0400	1-1/8	13/16	.078	
FC0401	1-3/16	7/8	.078	
FC0402	1-1/4	15/16	.078	

Material		
✓	Material Code (XX)	
B	Brass	
S	Steel	
SS	Stainless Steel	

✓	Compatible Finish (XX)	
	B, S, SS	0 - Plain
	B, S	5 - Nickel Plate (QQ-N-290)
	B, S	12 - Zinc Clear (ASTM-B-633)
	B, S	16 - Electro Tin (MIL-T-10727 TYPE 1)
	SS	20 - Passivation (MIL-F-14072D)
	B, S, SS	26 - Black Oxide
	B, S	28 - Zinc Yellow (ASTM-B-633)

Tolerances
Unless otherwise Specified
 .xxx +/- .005
 .xx +/- .010
 Angular +/- 1 Degree
 Linear +/- .005
Break all sharp edges



Source Control Drawing:
 To be produced by
 Fascomp Electronic Hardware

This document is the property of Fascomp Inc. and shall not be reproduced, distributed, or used as a basis for manufacturing without written permission from Fascomp Inc.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Fascomp:

[FC0389-SS](#) [FC0390-SS](#) [FC0391-SS](#) [FC0392-SS](#) [FC0393-SS](#) [FC0394-SS](#) [FC0395-SS](#) [FC0396-SS](#) [FC0397-SS](#)
[FC0398-SS](#)