


Captive Screw Type 4 10-32 Thread

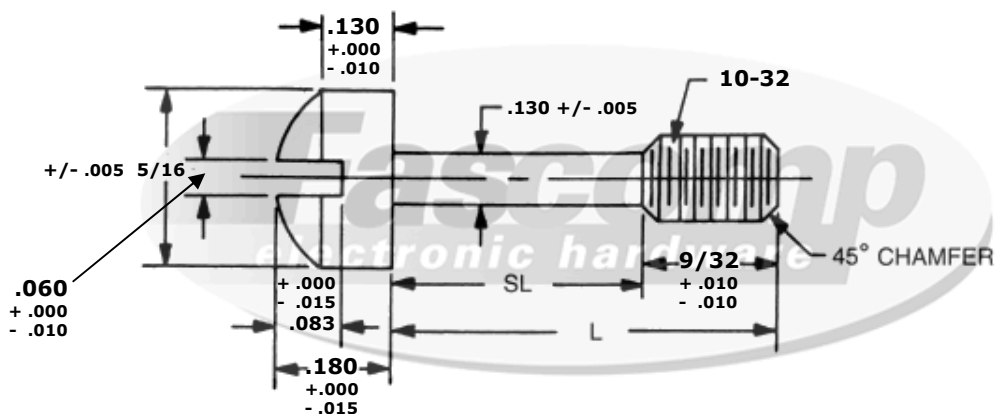

Create a part number:

Length	Material	Finish
FCXXXX	XX	XX

Captive Screws - 10-32 Thread			
✓	FCXXXX	Length (L)	S.L. +/- .010
	FC0877	3/8	3/32
	FC0878	7/16	5/32
	FC0879	1/2	7/32
	FC0880	9/16	9/32
	FC0881	5/8	11/32
	FC0882	11/16	13/32
	FC0883	3/4	15/32
	FC0884	13/16	17/32
	FC0885	7/8	19/32
	FC0886	15/16	21/32
	FC0887	1	23/32
	FC0888	1-1/16	25/32
	FC0889	1-1/8	27/32
	FC0890	1-3/16	29/32
	FC0891	1-1/4	31/32
	FC0892	1-5/16	1-1/32
	FC0893	1-3/8	1-3/32
	FC0894	1-7/16	1-5/32
	FC0895	1-1/2	1-7/32

Material		
✓	Material Code (XX)	
	B	Brass
	S	Steel
	SS	Stainless Steel

✓	Compatible Finish (XX)	
	B, S, SS	0 - Plain
	B, S	5 - Nickel Plate (QQ-N-290)
	B, S	12 - Zinc Clear (ASTM-B-633)
	B, S	16 - Electro Tin (MIL-T-10727 TYPE 1)
	SS	20 - Passivation (MIL-F-14072D)
	B, S, SS	26 - Black Oxide
	B, S	28 - Zinc Yellow (ASTM-B-633)

Tolerances
Unless otherwise Specified
 .xxx +/- .005
 .xx +/- .010
 Angular +/- 1 Degree
 Linear +/- .005
Break all sharp edges

Source Control Drawing:
 To be produced by
 Fascomp Electronic Hardware



This document is the property of Fascomp Inc. and shall not be reproduced, distributed, or used as a basis for manufacturing without written permission from Fascomp Inc.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Fascomp:

[FC0877-SS](#) [FC0878-SS](#) [FC0879-SS](#) [FC0880-SS](#) [FC0881-SS](#) [FC0882-SS](#) [FC0883-SS](#) [FC0884-SS](#) [FC0885-SS](#)
[FC0886-SS](#) [FC0887-SS](#) [FC0891-SS](#)