


Captive Screw Type 4 2-56 Thread

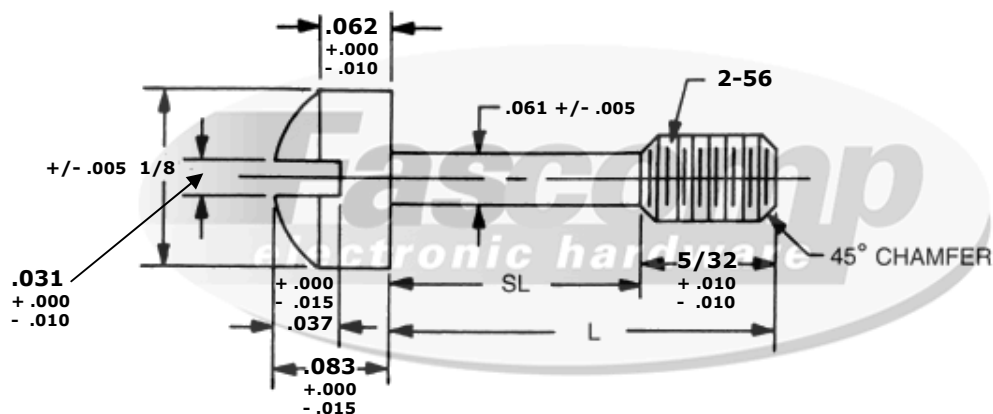

Create a part number:

Length	Material	Finish
FCXXXX	XX	XX

Captive Screws - 2-56 Thread			
✓	FCXXXX	Length (L)	S.L. +/- .010
	FC0799	1/4	3/32
	FC0800	5/16	5/32
	FC0801	3/8	7/32
	FC0802	7/16	9/32
	FC0803	1/2	11/32
	FC0804	9/16	13/32
	FC0805	5/8	15/32
	FC0806	11/16	17/32
	FC0807	3/4	19/32

Material		
✓	Material Code (XX)	
	B	Brass
	S	Steel
	SS	Stainless Steel

✓	Compatible Finish (XX)	
	B, S, SS	0 - Plain
	B, S	5 - Nickel Plate (QQ-N-290)
	B, S	12 - Zinc Clear (ASTM-B-633)
	B, S	16 - Electro Tin (MIL-T-10727 TYPE 1)
	SS	20 - Passivation (MIL-F-14072D)
	B, S, SS	26 - Black Oxide
	B, S	28 - Zinc Yellow (ASTM-B-633)

Tolerances
Unless otherwise Specified
 .xxx +/- .005
 .xx +/- .010
 Angular +/- 1 Degree
 Linear +/- .005
Break all sharp edges



Source Control Drawing:
 To be produced by
 Fascomp Electronic Hardware

This document is the property of Fascomp Inc. and shall not be reproduced, distributed, or used as a basis for manufacturing without written permission from Fascomp Inc.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Fascomp:](#)

[FC0799-SS](#) [FC0800-SS](#) [FC0801-SS](#) [FC0802-SS](#) [FC0803-SS](#) [FC0804-SS](#) [FC0805-SS](#) [FC0806-SS](#) [FC0807-SS](#)