


Captive Screw Type 4 6-32 Thread

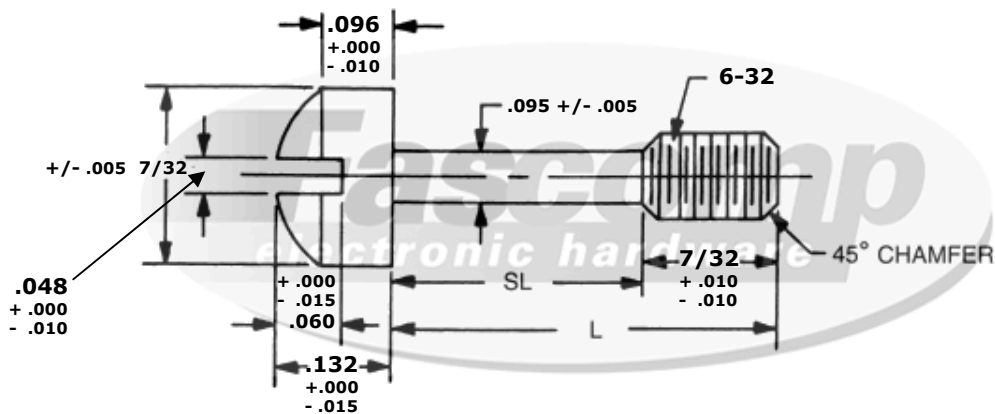

Create a part number:

Length	Material	Finish
FCXXXX	XX	XX

Captive Screws - 6-32 Thread			
✓	FCXXXX	Length (L)	S.L. +/- .010
	FC0830	5/16	3/32
	FC0831	3/8	5/32
	FC0832	7/16	7/32
	FC0833	1/2	9/32
	FC0834	9/16	11/32
	FC0835	5/8	13/32
	FC0836	11/16	15/32
	FC0837	3/4	17/32
	FC0838	13/16	19/32
	FC0839	7/8	21/32
	FC0840	15/16	23/32
	FC0841	1	25/32

Material		
✓	Material Code (XX)	
	B	Brass
	S	Steel
	SS	Stainless Steel

✓	Compatible Finish (XX)	
	B, S, SS	0 - Plain
	B, S	5 - Nickel Plate (QQ-N-290)
	B, S	12 - Zinc Clear (ASTM-B-633)
	B, S	16 - Electro Tin (MIL-T-10727 TYPE 1)
	SS	20 - Passivation (MIL-F-14072D)
	B, S, SS	26 - Black Oxide
	B, S	28 - Zinc Yellow (ASTM-B-633)

Tolerances
Unless otherwise Specified
 .xxx +/- .005
 .xx +/- .010
 Angular +/- 1 Degree
 Linear +/- .005
Break all sharp edges

Source Control Drawing:
 To be produced by
 Fascomp Electronic Hardware



This document is the property of Fascomp Inc. and shall not be reproduced, distributed, or used as a basis for manufacturing without written permission from Fascomp Inc.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Fascomp:

[CFC841-SS](#) [CFC833-SS](#) [CFC831-SS](#) [CFC832-SS](#) [CFC839-SS](#) [CFC830-SS](#) [CFC835-SS](#) [CFC837-SS](#)