


Hex Code Table		
✓	FCXXXX	Length (L)
	FC2098	1/8
	FC2099	3/16
	FC2100	1/4
	FC2101	5/16
	FC2102	3/8
	FC2103	7/16
	FC2104	1/2
	FC2105	9/16
	FC2106	5/8
	FC2107	11/16
	FC2108	3/4
	FC2109	13/16
	FC2110	7/8
	FC2111	15/16
	FC2112	1
	FC2113	1-1/16
	FC2114	1-1/8
	FC2115	1-3/16
	FC2116	1-1/4
	FC2117	1-5/16
	FC2118	1-3/8
	FC2119	1-7/16
	FC2120	1-1/2
	FC2121	1-9/16
	FC2122	1-5/8
	FC2123	1-11/16
	FC2124	1-3/4
	FC2125	1-13/16
	FC2126	1-7/8
	FC2127	1-15/16
	FC2128	2
	FC2129	2-1/8
	FC2130	2-1/4
	FC2131	2-3/8
	FC2132	2-1/2
	FC2133	2-5/8
	FC2134	2-3/4
	FC2135	2-7/8
	FC2136	3
	FC2137	3-1/4
	FC2138	3-1/2
	FC2139	3-3/4
	FC2140	4
	FC2141	4-1/4
	FC2142	4-1/2
	FC2143	4-3/4
	FC2144	5
	FC2145	5-1/4
	FC2146	5-1/2
	FC2147	5-3/4
	FC2148	6

1/4 Hex Female Standoff

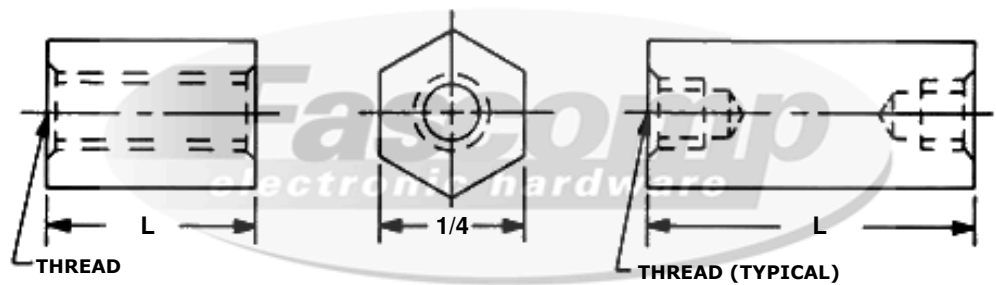

Create a part number:

Length	Thread	Material	Finish
FCXXXX	XXX	XX	XX
_____ - _____ - _____ - _____			

✓	Thread			
	Thread Code	Tapped Thru		Longer Parts
	(XXX)	A, B, S	SS	Blind Tap Depth
	440	1	3/4	1/4
	632	1	1	3/8
	832	1	1	7/16
	1032	1-1/8	1	1/2

Aluminum (A), Brass (B), Steel (S), Stainless Steel (SS)

Material		
✓	Material Code (XX)	
	A	Aluminum
	B	Brass
	S	Steel
	SS	Stainless Steel
	N	Nylon

Tolerances
Unless otherwise Specified
 .xxx +/- .005
 .xx +/- .010
 Angular +/- 1 Degree
 Linear +/- .005
Break all sharp edges

✓	Compatible Finish	
	A, B, S, SS	0 - Plain
	B, S	5 - Nickel Plate (QQ-N-290)
	A	6 - Iridite #14 Gold (MIL-C-5541E)
	A	7 - Iridite Clear (MIL-C-5541E)
	A	9 - Alodine 1200
	B, S	12 - Zinc Clear (ASTM-B-633)
	B, S	16 - Electro Tin (MIL-T-10727 TYPE 1)
	SS	20 - Passivation (MIL-F-14072D)
	A	22 - Clear Anodize (MIL-A-8625-TYPE2) (Sulphuric) Hot Water Seal (Clear)
	A	24 - Black Anodize (MIL-A-8625)
	B, S, SS	26 - Black Oxide
	B, S	28 - Zinc Yellow (ASTM-B-633)



Source Control Drawing:
 To be produced by
 Fascomp Electronic Hardware

This document is the property of Fascomp Inc. and shall not be reproduced, distributed or used as a basis for manufacturing without written permission from Fascomp Inc.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Fascomp:

[2134-632-SS](#) [FC2134-632-SS](#) [FC2101-632-SS](#) [FC2109-832-SS](#) [FC2110-440-SS](#) [FC2108-832-A](#) [FC2107-632-SS](#)
[FC2108-440-SS](#) [FC2102-832-A](#) [FC2100-632-A](#) [FC2104-632-SS](#) [FC2107-632-A](#) [FC2106-632-A](#) [FC2105-832-A](#)
[FC2103-440-SS](#) [FC2110-832-SS](#) [FC2100-440-SS](#) [FC2111-632-A](#) [FC2098-832-SS](#) [FC2098-832-A](#) [FC2112-632-SS](#)
[FC2102-632-A](#) [FC2112-632-A](#) [FC2101-440-SS](#) [FC2100-832-A](#) [FC2104-440-SS](#) [FC2106-832-A](#) [FC2102-440-SS](#)
[FC2105-440-SS](#) [FC2103-832-A](#) [FC2101-832-A](#) [FC2106-440-SS](#) [FC2107-832-A](#) [FC2098-632-SS](#) [FC2110-632-A](#)
[FC2099-832-A](#) [FC2107-440-SS](#) [FC2111-632-SS](#) [FC2104-832-A](#) [FC2109-440-SS](#) [FC2099-832-SS](#) [FC2099-632-SS](#)
[FC2111-832-SS](#) [FC2107-440-A](#) [FC2104-632-A](#) [FC2112-832-SS](#) [FC2110-832-A](#) [FC2110-632-SS](#) [FC2098-632-A](#)
[FC2109-440-A](#) [FC2105-632-A](#) [FC2105-440-A](#) [FC2106-440-A](#) [FC2101-632-A](#) [FC2111-832-A](#) [FC2100-632-SS](#)
[FC2111-440-A](#) [FC2100-440-A](#) [FC2103-632-A](#) [FC2112-832-A](#) [FC2103-440-A](#) [FC2102-632-SS](#) [FC2108-632-SS](#)
[FC2099-632-A](#) [FC2106-632-SS](#) [FC2104-440-A](#) [FC2098-440-SS](#) [FC2101-440-A](#) [FC2108-832-SS](#) [FC2112-440-A](#)
[FC2100-832-SS](#) [FC2098-440-A](#) [FC2102-440-A](#) [FC2104-832-SS](#) [FC2102-832-SS](#) [FC2107-832-SS](#) [FC2110-440-A](#)
[FC2109-632-SS](#) [FC2108-632-A](#) [FC2108-440-A](#) [FC2101-832-SS](#) [FC2103-632-SS](#) [FC2105-632-SS](#) [FC2103-832-SS](#)
[FC2105-832-SS](#) [FC2109-632-A](#) [FC2109-832-A](#) [FC2111-440-SS](#) [FC2106-832-SS](#) [FC2099-440-SS](#) [FC2099-440-A](#)
[FC2112-440-SS](#) [FC2136-632-SS](#)