


# 3/16 Round Internal Thread Handles

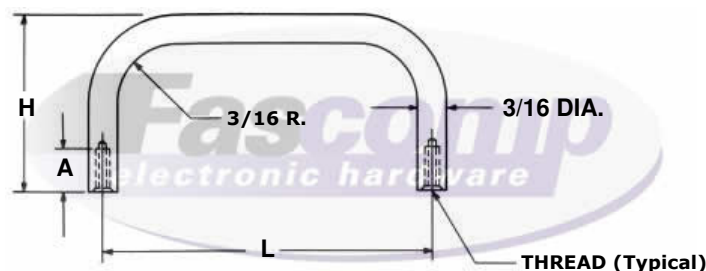

| FCXXXX | Length (L)<br>+/- .031 | Leg Height (H)<br>+/- .031 |
|--------|------------------------|----------------------------|
| FC8048 | 1-1/2                  | 5/8                        |
| FC8049 | 1-3/4                  | 5/8                        |
| FC8050 | 2                      | 5/8                        |
| FC8051 | 3                      | 5/8                        |
| FC8052 | 4                      | 5/8                        |
| FC8053 | 5                      | 5/8                        |
| FC8054 | 1                      | 3/4                        |
| FC8055 | 1-1/4                  | 3/4                        |
| FC8056 | 1-1/2                  | 3/4                        |
| FC8057 | 1-3/4                  | 3/4                        |
| FC8058 | 2                      | 3/4                        |
| FC8059 | 3                      | 3/4                        |
| FC8060 | 4                      | 3/4                        |
| FC8061 | 5                      | 3/4                        |
| FC8062 | 1                      | 7/8                        |
| FC8063 | 1-1/4                  | 7/8                        |
| FC8064 | 1-1/2                  | 7/8                        |
| FC8065 | 1-3/4                  | 7/8                        |
| FC8066 | 2                      | 7/8                        |
| FC8067 | 3                      | 7/8                        |
| FC8068 | 4                      | 7/8                        |
| FC8069 | 5                      | 7/8                        |
| FC8070 | 1                      | 1                          |
| FC8071 | 1-1/4                  | 1                          |
| FC8072 | 1-1/2                  | 1                          |
| FC8073 | 1-3/4                  | 1                          |
| FC8074 | 2                      | 1                          |
| FC8075 | 3                      | 1                          |
| FC8076 | 4                      | 1                          |
| FC8077 | 5                      | 1                          |
| FC8078 | 1                      | 1-1/8                      |
| FC8079 | 1-1/4                  | 1-1/8                      |
| FC8080 | 1-1/2                  | 1-1/8                      |
| FC8081 | 1-3/4                  | 1-1/8                      |
| FC8082 | 2                      | 1-1/8                      |
| FC8083 | 3                      | 1-1/8                      |
| FC8084 | 4                      | 1-1/8                      |
| FC8085 | 5                      | 1-1/8                      |
| FC8086 | 1                      | 1-1/4                      |
| FC8087 | 1-1/4                  | 1-1/4                      |
| FC8088 | 1-1/2                  | 1-1/4                      |
| FC8089 | 1-3/4                  | 1-1/4                      |
| FC8090 | 2                      | 1-1/4                      |
| FC8091 | 3                      | 1-1/4                      |
| FC8092 | 4                      | 1-1/4                      |
| FC8093 | 5                      | 1-1/4                      |
| FC8094 | 1                      | 1-1/2                      |
| FC8095 | 1-1/4                  | 1-1/2                      |
| FC8096 | 1-1/2                  | 1-1/2                      |
| FC8097 | 1-3/4                  | 1-1/2                      |
| FC8098 | 2                      | 1-1/2                      |
| FC8099 | 3                      | 1-1/2                      |
| FC8100 | 4                      | 1-1/2                      |
| FC8101 | 5                      | 1-1/2                      |

Create a part number:

| Part                          | Thread | Material | Finish |
|-------------------------------|--------|----------|--------|
| FCXXXX                        | XXX    | XX       | XX     |
| _____ - _____ - _____ - _____ |        |          |        |

| Thread (A)                                 |        |            |  |
|--------------------------------------------|--------|------------|--|
| Short lengths, 'A' tapped to maximum depth |        |            |  |
| Code (XXX)                                 | Thread | (A)        |  |
| 440                                        | 4-40   | 1/4        |  |
| 632                                        | 6-32   | 5/16 - 3/8 |  |

| Material           |                 |  |
|--------------------|-----------------|--|
| Material Code (XX) |                 |  |
| A                  | Aluminum        |  |
| B                  | Brass           |  |
| SS                 | Stainless Steel |  |

| Compatible Finish |                                                                          |  |
|-------------------|--------------------------------------------------------------------------|--|
| A, B, S, SS       | 0 - Plain                                                                |  |
| B, S              | 5 - Nickel Plate (QQ-N-290)                                              |  |
| A                 | 6 - Iridite #14 Gold (MIL-C-5541E)                                       |  |
| A                 | 7 - Iridite Clear (MIL-C-5541E)                                          |  |
| A                 | 9 - Alodine 1200                                                         |  |
| B, S              | 12 - Zinc Clear (ASTM-B-633)                                             |  |
| B, S              | 16 - Electro Tin (MIL-T-10727 TYPE 1)                                    |  |
| SS                | 20 - Passivation (MIL-F-14072D)                                          |  |
| A                 | 22 - Clear Anodize (MIL-A-8625-TYPE2) (Sulphuric) Hot Water Seal (Clear) |  |
| A                 | 24 - Black Anodize (MIL-A-8625)                                          |  |
| B, S, SS          | 26 - Black Oxide                                                         |  |
| B, S              | 28 - Zinc Yellow (ASTM-B-633)                                            |  |

**Tolerances**  
**Unless otherwise Specified**  
 .xxx +/- .005  
 .xx +/- .010  
 Angular +/- 1 Degree  
 Linear +/- .005  
**Break all sharp edges**

Source Control Drawing:  
 To be produced by  
 Fascomp Electronic Hardware

This document is the property of  
 Fascomp Inc. and shall not be  
 reproduced, distributed or used as a  
 basis for manufacturing without  
 written permission from Fascomp  
 Inc.



# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

## Fascomp:

[FC8048-632-A](#) [FC8048-632-A-24](#) [FC8048-632-SS](#) [FC8049-632-A](#) [FC8049-632-A-24](#) [FC8049-632-SS](#) [FC8050-632-A](#) [FC8050-632-A-24](#) [FC8050-632-SS](#) [FC8051-632-A](#) [FC8051-632-A-24](#) [FC8051-632-SS](#) [FC8053-632-A](#) [FC8053-632-A-24](#) [FC8053-632-SS](#) [FC8054-632-A](#) [FC8054-632-A-24](#) [FC8054-632-SS](#) [FC8055-632-A](#) [FC8055-632-A-24](#) [FC8055-632-SS](#) [FC8057-632-A](#) [FC8057-632-A-24](#) [FC8057-632-SS](#) [FC8059-632-A](#) [FC8059-632-A-24](#) [FC8059-632-SS](#)