


Hex Length Table		
✓ FCXXXX	Length (L)	
FC4571	1/4	
FC4572	5/16	
FC4573	3/8	
FC4574	7/16	
FC4575	1/2	
FC4576	9/16	
FC4577	5/8	
FC4578	11/16	
FC4579	3/4	
FC4580	13/16	
FC4581	7/8	
FC4582	15/16	
FC4583	1	
FC4584	1-1/16	
FC4585	1-1/8	
FC4586	1-3/16	
FC4587	1-1/4	
FC4588	1-5/16	
FC4589	1-3/8	
FC4590	1-7/16	
FC4591	1-1/2	
FC4592	1-9/16	
FC4593	1-5/8	
FC4594	1-11/16	
FC4595	1-3/4	
FC4596	1-13/16	
FC4597	1-7/8	
FC4598	1-15/16	
FC4599	2	
FC4600	2-1/8	
FC4601	2-1/4	
FC4602	2-3/8	
FC4603	2-1/2	
FC4604	2-5/8	
FC4605	2-3/4	
FC4606	2-7/8	
FC4607	3	
FC4608	3-1/4	
FC4609	3-1/2	
FC4610	3-3/4	
FC4611	4	
FC4612	4-1/4	
FC4613	4-1/2	
FC4614	4-3/4	
FC4615	5	
FC4616	5-1/4	
FC4617	5-1/2	
FC4618	5-3/4	
FC4619	6	

5/16 Hex Male-Female Standoff

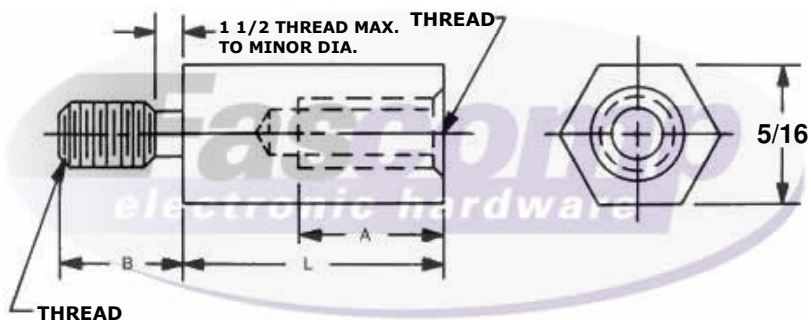

Create a part number:

Length	Thread	Material	Finish
FCXXXX	XXX	XX	XX
_____ - _____ - _____ - _____			

Thread			
Short lengths, 'A' tapped to maximum depth			
✓ Thread Code (XXX)	Depth (A)	Length (B)	
440	1/4	3/16	
632	3/8	1/4	
832	7/16	3/8	
1032	1/2	3/8	

Material		
✓ Material Code (XX)		
A	Aluminum	
B	Brass	
S	Steel	
SS	Stainless Steel	
N	Nylon	

Tolerances Unless otherwise Specified
 .xxx +/- .005
 .xx +/- .010
 Angular +/- 1 Degree
 Linear +/- .005
Break all sharp edges

✓ Compatible Finish		
A, B, S, SS	0 - Plain	
B, S	5 - Nickel Plate (QQ-N-290)	
A	6 - Iridite #14 Gold (MIL-C-5541E)	
A	7 - Iridite Clear (MIL-C-5541E)	
A	9 - Alodine 1200	
B, S	12 - Zinc Clear (ASTM-B-633)	
B, S	16 - Electro Tin (MIL-T-10727 TYPE 1)	
SS	20 - Passivation (MIL-F-14072D)	
A	22 - Clear Anodize (MIL-A-8625-TYPE2) (Sulphuric) Hot Water Seal (Clear)	
A	24 - Black Anodize (MIL-A-8625)	
B, S, SS	26 - Black Oxide	
B, S	28 - Zinc Yellow (ASTM-B-633)	



Source Control Drawing:
 To be produced by
 Fascomp Electronic Hardware

This document is the property of Fascomp Inc. and shall not be reproduced, distributed, or used as a basis for manufacturing without written permission from Fascomp Inc.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Fascomp:

[FC4577-1032-SS](#) [FC4577-632-A](#) [FC4577-632-SS](#) [FC4577-832-A](#) [FC4577-832-SS](#) [FC4578-1032-A](#) [FC4576-632-A](#)
[FC4576-632-SS](#) [FC4576-832-A](#) [FC4576-832-SS](#) [FC4577-1032-A](#) [FC4575-632-A](#) [FC4575-632-SS](#) [FC4575-832-A](#)
[FC4575-832-SS](#) [FC4576-1032-A](#) [FC4576-1032-SS](#) [FC4574-632-A](#) [FC4574-632-SS](#) [FC4574-832-A](#) [FC4574-832-SS](#)
[FC4575-1032-A](#) [FC4575-1032-SS](#) [FC4573-632-A](#) [FC4573-632-SS](#) [FC4573-832-A](#) [FC4573-832-SS](#) [FC4574-1032-](#)
[A](#) [FC4574-1032-SS](#) [FC4572-632-A](#) [FC4572-632-SS](#) [FC4572-832-A](#) [FC4572-832-SS](#) [FC4573-1032-A](#) [FC4573-](#)
[1032-SS](#) [FC4572-1032-A](#) [FC4581-632-SS](#) [FC4581-832-A](#) [FC4581-832-SS](#) [FC4582-1032-A](#) [FC4572-1032-SS](#)
[FC4583-1032-A](#) [FC4583-632-A](#) [FC4583-632-SS](#) [FC4583-832-A](#) [FC4583-832-SS](#) [FC4571-832-SS](#) [FC4571-832-A](#)
[FC4582-1032-SS](#) [FC4582-632-A](#) [FC4582-632-SS](#) [FC4582-832-A](#) [FC4582-832-SS](#) [FC4581-1032-SS](#) [FC4581-632-A](#)
[FC4571-1032-A](#) [FC4571-1032-SS](#) [FC4571-632-A](#) [FC4571-632-SS](#) [FC4580-1032-SS](#) [FC4580-632-A](#) [FC4580-632-](#)
[SS](#) [FC4580-832-A](#) [FC4580-832-SS](#) [FC4581-1032-A](#) [FC4579-1032-SS](#) [FC4579-632-A](#) [FC4579-632-SS](#) [FC4579-](#)
[832-A](#) [FC4579-832-SS](#) [FC4580-1032-A](#) [FC4578-1032-SS](#) [FC4578-632-A](#) [FC4578-632-SS](#) [FC4578-832-A](#) [FC4578-](#)
[832-SS](#) [FC4579-1032-A](#)