


Hex Length Table		
✓ FCXXXX	Length (L)	
FC4071	1/4	
FC4072	5/16	
FC4073	3/8	
FC4074	7/16	
FC4075	1/2	
FC4076	9/16	
FC4077	5/8	
FC4078	11/16	
FC4079	3/4	
FC4080	13/16	
FC4081	7/8	
FC4082	15/16	
FC4083	1	
FC4084	1-1/16	
FC4085	1-1/8	
FC4086	1-3/16	
FC4087	1-1/4	
FC4088	1-5/16	
FC4089	1-3/8	
FC4090	1-7/16	
FC4091	1-1/2	
FC4092	1-9/16	
FC4093	1-5/8	
FC4094	1-11/16	
FC4095	1-3/4	
FC4096	1-13/16	
FC4097	1-7/8	
FC4098	1-15/16	
FC4099	2	
FC4100	2-1/8	
FC4101	2-1/4	
FC4102	2-3/8	
FC4103	2-1/2	
FC4104	2-5/8	
FC4105	2-3/4	
FC4106	2-7/8	
FC4107	3	
FC4108	3-1/4	
FC4109	3-1/2	
FC4110	3-3/4	
FC4111	4	
FC4112	4-1/4	
FC4113	4-1/2	
FC4114	4-3/4	
FC4115	5	
FC4116	5-1/4	
FC4117	5-1/2	
FC4118	5-3/4	
FC4119	6	

5/16 Round Male-Female Standoff

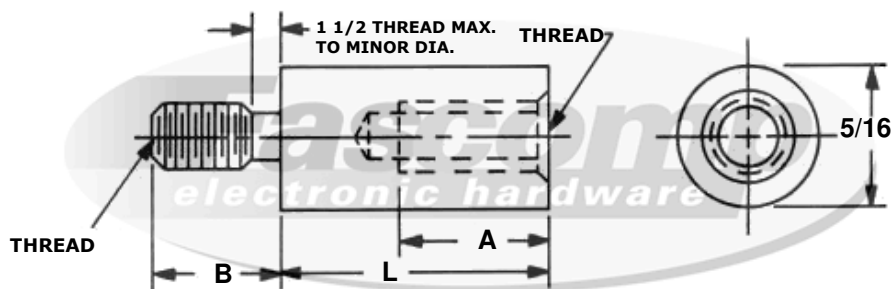

Create a part number:

Length	Thread	Material	Finish
FCXXXX	XXX	XX	XX
_____ - _____ - _____ - _____			

Thread			
Short lengths, 'A' tapped to maximum depth			
✓ Thread Code (XXX)	Depth (A)	Length (B)	
440	1/4	3/16	
632	3/8	1/4	
832	7/16	3/8	
1032	1/2	3/8	

Material		
✓ Material Code (XX)		
A	Aluminum	
B	Brass	
S	Steel	
SS	Stainless Steel	
N	Nylon	

Tolerances Unless otherwise Specified
 .xxx +/- .005
 .xx +/- .010
 Angular +/- 1 Degree
 Linear +/- .005
Break all sharp edges

✓ Compatible Finish		
A, B, S, SS	0 - Plain	
B, S	5 - Nickel Plate (QQ-N-290)	
A	6 - Iridite #14 Gold (MIL-C-5541E)	
A	7 - Iridite Clear (MIL-C-5541E)	
A	9 - Alodine 1200	
B, S	12 - Zinc Clear (ASTM-B-633)	
B, S	16 - Electro Tin (MIL-T-10727 TYPE 1)	
SS	20 - Passivation (MIL-F-14072D)	
A	22 - Clear Anodize (MIL-A-8625-TYPE2) (Sulphuric) Hot Water Seal (Clear)	
A	24 - Black Anodize (MIL-A-8625)	
B, S, SS	26 - Black Oxide	
B, S	28 - Zinc Yellow (ASTM-B-633)	



Source Control Drawing:
 To be produced by
 Fascomp Electronic Hardware

This document is the property of Fascomp Inc. and shall not be reproduced, distributed, or used as a basis for manufacturing without written permission from Fascomp Inc.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Fascomp:](#)

[FC4079-1032-SS](#) [FC4103-832-B-12](#) [FC4072-440-SS](#) [FC4111-832-A](#) [FC4074-832-N](#) [FC4108-1032-A](#) [FC4079-1032-N](#) [FC4075-1032-SS](#) [FC4107-1032-SS](#)