



## Part Number: D4I0810S


### Electrical Specifications

Frequency Range (GHz):	0.8 – 1.0
Isolation (dB):	40 MIN
Insertion Loss (dB):	0.8 MAX
VSWR:	1.25:1 MIN
Forward Power (W):	200 AVG 750 PK
Reflective Power (W):	10 AVG


### Mechanical/Environmental Specifications

Connector Type:	SMA
Connector Body:	Passivated stainless steel
Connector Pin:	Gold plated copper
Load Body:	Brass
Magnetic Shunt:	Nickel plated CRS
Operational Temp:	-20°C to +65°C
Weight (oz)	5.5 MAX

### D4I0810S Dimensions

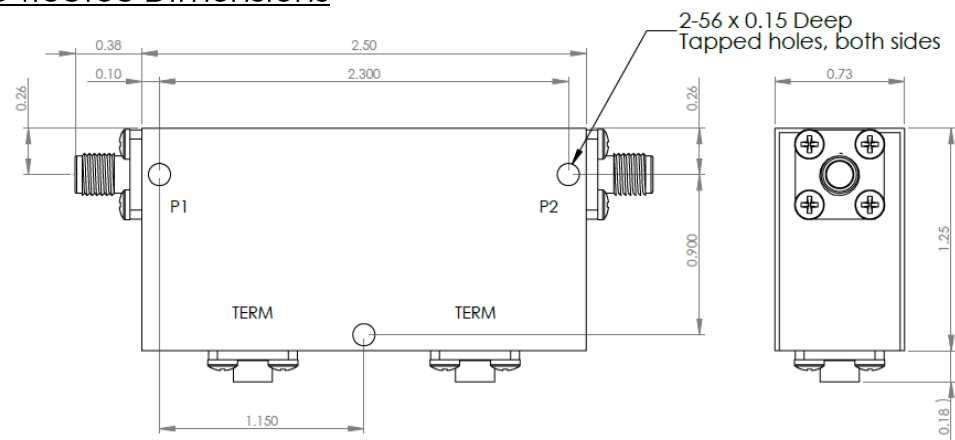

### D4I0810S-3 Dimensions

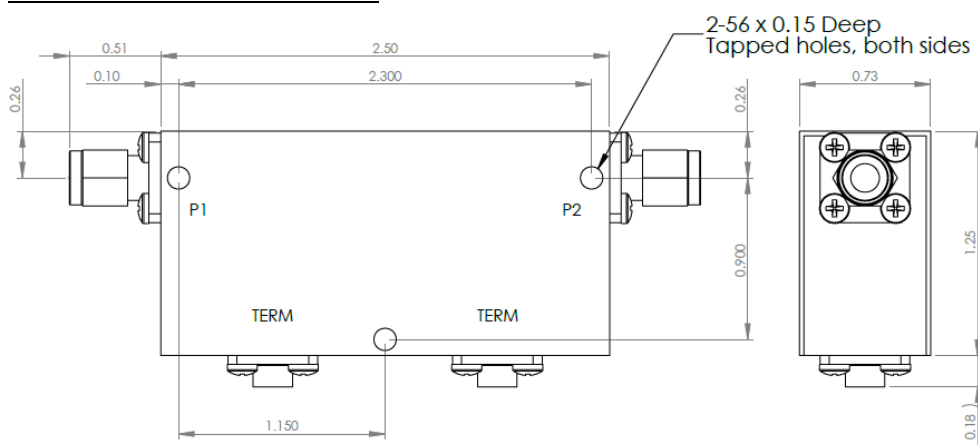


Dimensions are in inches  
Tolerance  
XX ±0.03  
XXX ±0.010

Type of Device	PN Suffix	Connector Configuration Input / Output	PN Example
Single and Dual Junction Isolator, 2-Port Device  Input / Output	N/A	Female / Female	D4I0810S
	-1	Male / Female	D4I0810S-1
	-2	Female / Male	D4I0810S-2
	-3	Male / Male	D4I0810S-3



## MEASURED DATA

Part Number: D4I0810S, +25°C

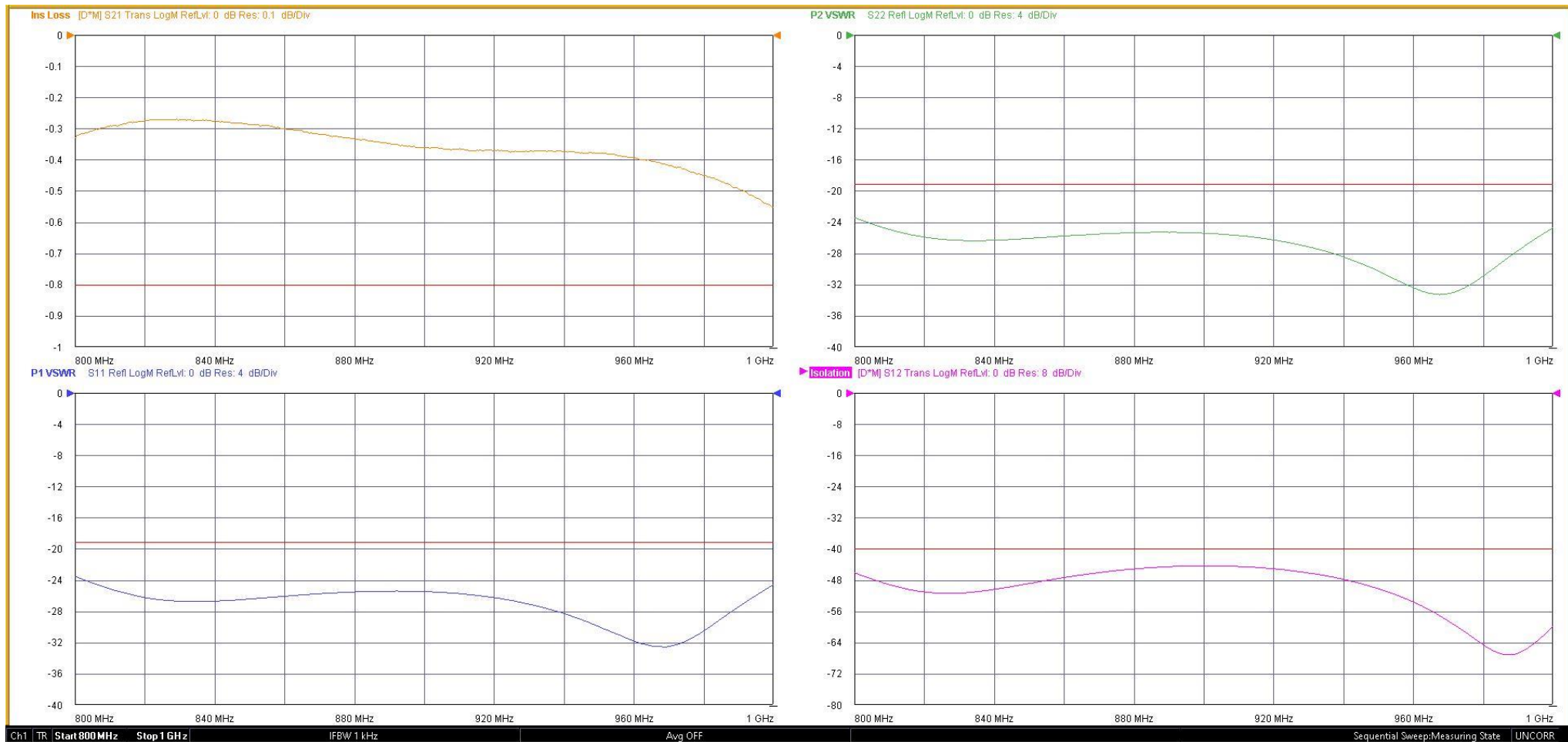

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DiTom:](#)

[D3I0810S](#) [D3I0810S-1](#) [D3I0810S-2](#) [D3I0810S-3](#)