



## Part Number: D4I4080


### Electrical Specifications

Frequency Range (GHz):	4.0 – 8.0
Isolation (dB):	40 MIN
Insertion Loss (dB):	0.8 MAX
VSWR:	1.25:1 MIN
Forward Power (W):	30 AVG 50 PK
Reflective Power (W):	2 AVG


### Mechanical/Environmental Specifications

Connector Type:	SMA
Connector Body:	Passivated stainless steel
Connector Pin:	Gold plated copper
Load Body:	Brass
Magnetic Shunt:	Nickel plated CRS
Operational Temp:	-10°C to +60°C
Weight (oz)	4.0 MAX

D4I4080 Dimensions

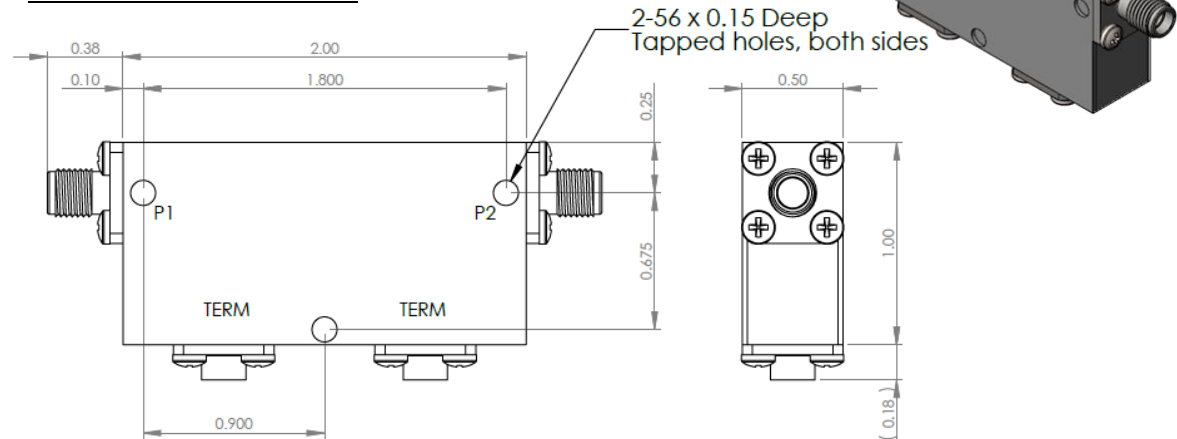

D4I4080-3 Dimensions

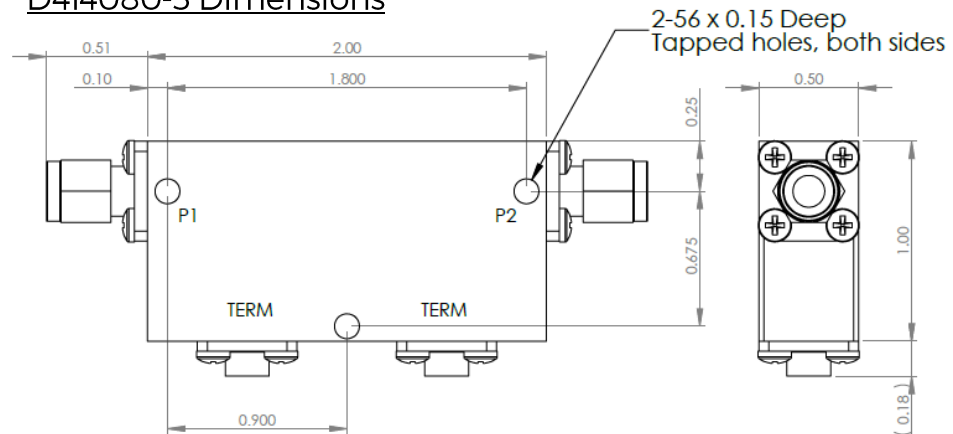


Dimensions are in inches  
Tolerance  
XX ±0.03  
XXX ±0.010

Type of Device	PN Suffix	Connector Configuration Input / Output	PN Example
Single and Dual Junction Isolator, 2-Port Device  Input / Output	N/A	Female / Female	D4I4080
	-1	Male / Female	D4I4080-1
	-2	Female / Male	D4I4080-2
	-3	Male / Male	D4I4080-3



## MEASURED DATA

Part Number: D4I4080, +25°C

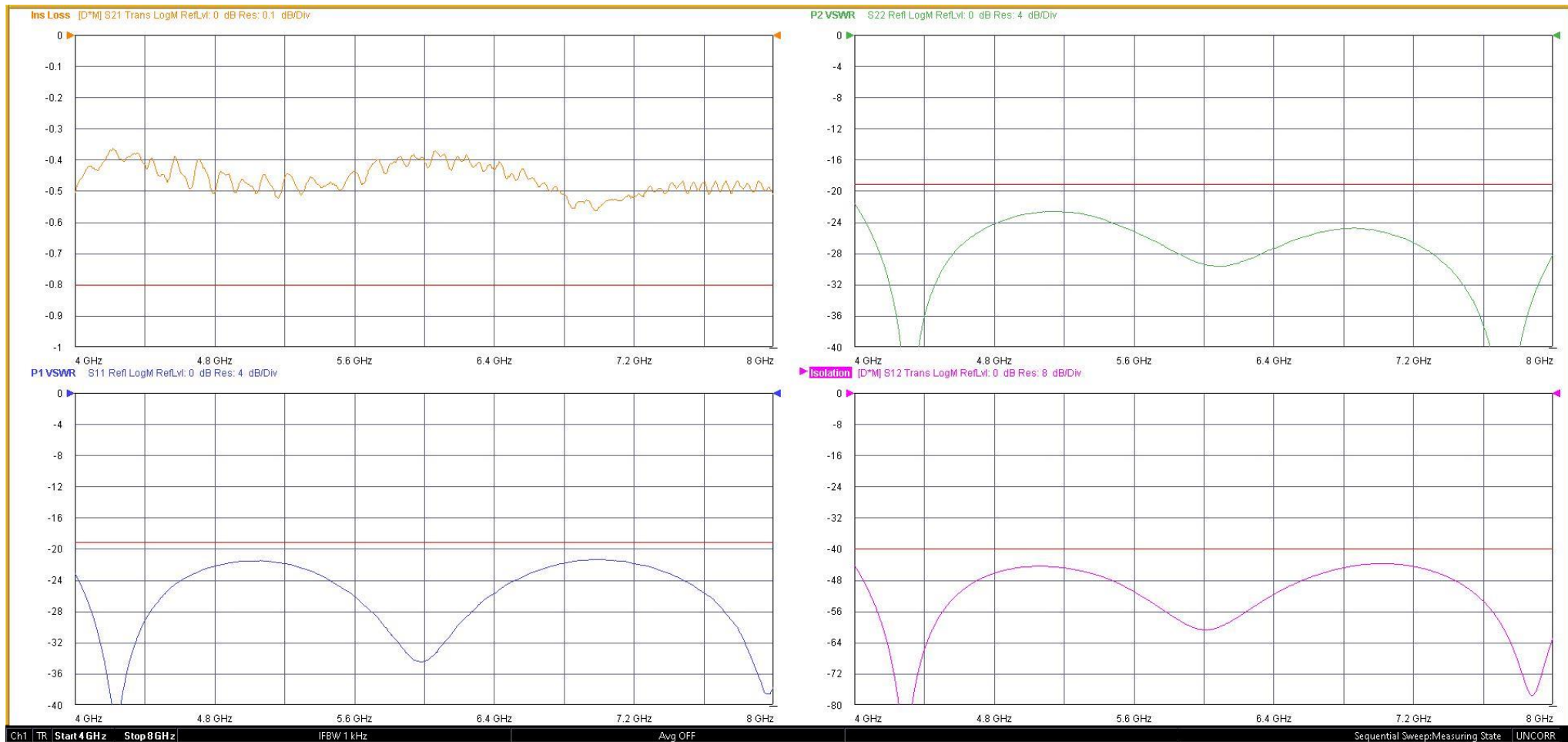

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DiTom:](#)

[D4I4080](#) [D4I4080-1](#) [D4I4080-2](#) [D4I4080-3](#)