



Part Number: D4I7018


Electrical Specifications

Frequency Range (GHz):	7.0 – 18.0
Isolation (dB):	30 MIN
Insertion Loss (dB):	2.0 MAX
VSWR:	1.5:1 MIN
Forward Power (W):	10 AVG 30 PK
Reflective Power (W):	2 AVG


Mechanical/Environmental Specifications

Connector Type:	SMA
Connector Body:	Passivated stainless steel
Connector Pin:	Gold plated copper
Load Body:	Brass
Magnetic Shunt:	Nickel plated CRS
Operational Temp:	-10°C to +85°C
Weight (oz)	2.0 MAX

D4I7018 Dimensions

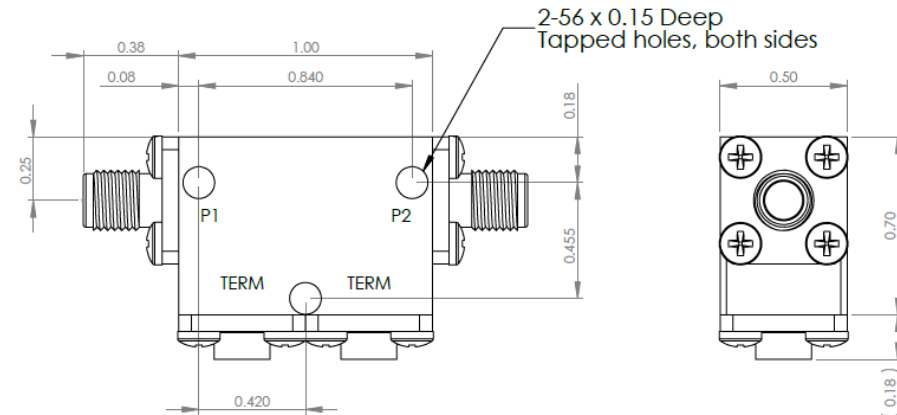


D4I7018-3 Dimensions

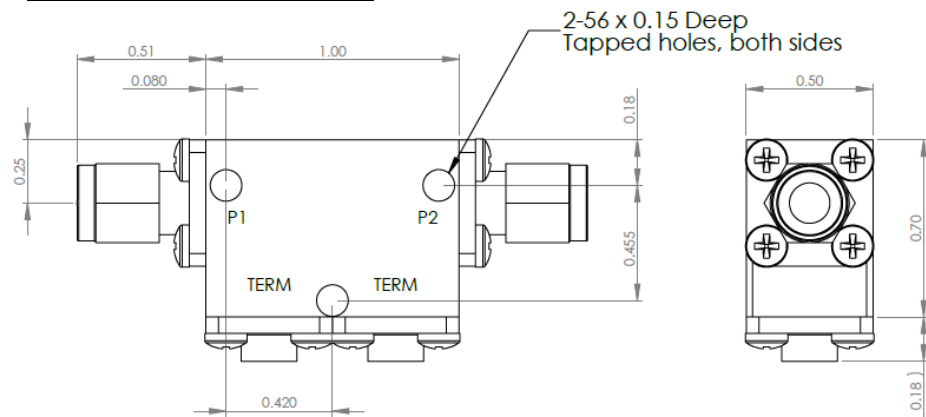


Dimensions are in inches
Tolerance
XX ±0.03
XXX ±0.010

Type of Device	PN Suffix	Connector Configuration Input / Output	PN Example
Single and Dual Junction Isolator, 2-Port Device Input / Output	N/A	Female / Female	D4I7018
	-1	Male / Female	D4I7018-1
	-2	Female / Male	D4I7018-2
	-3	Male / Male	D4I7018-3

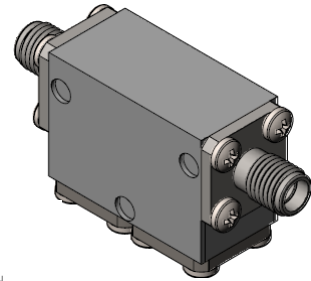

MEASURED DATA

Part Number: D4I7018, +25°C

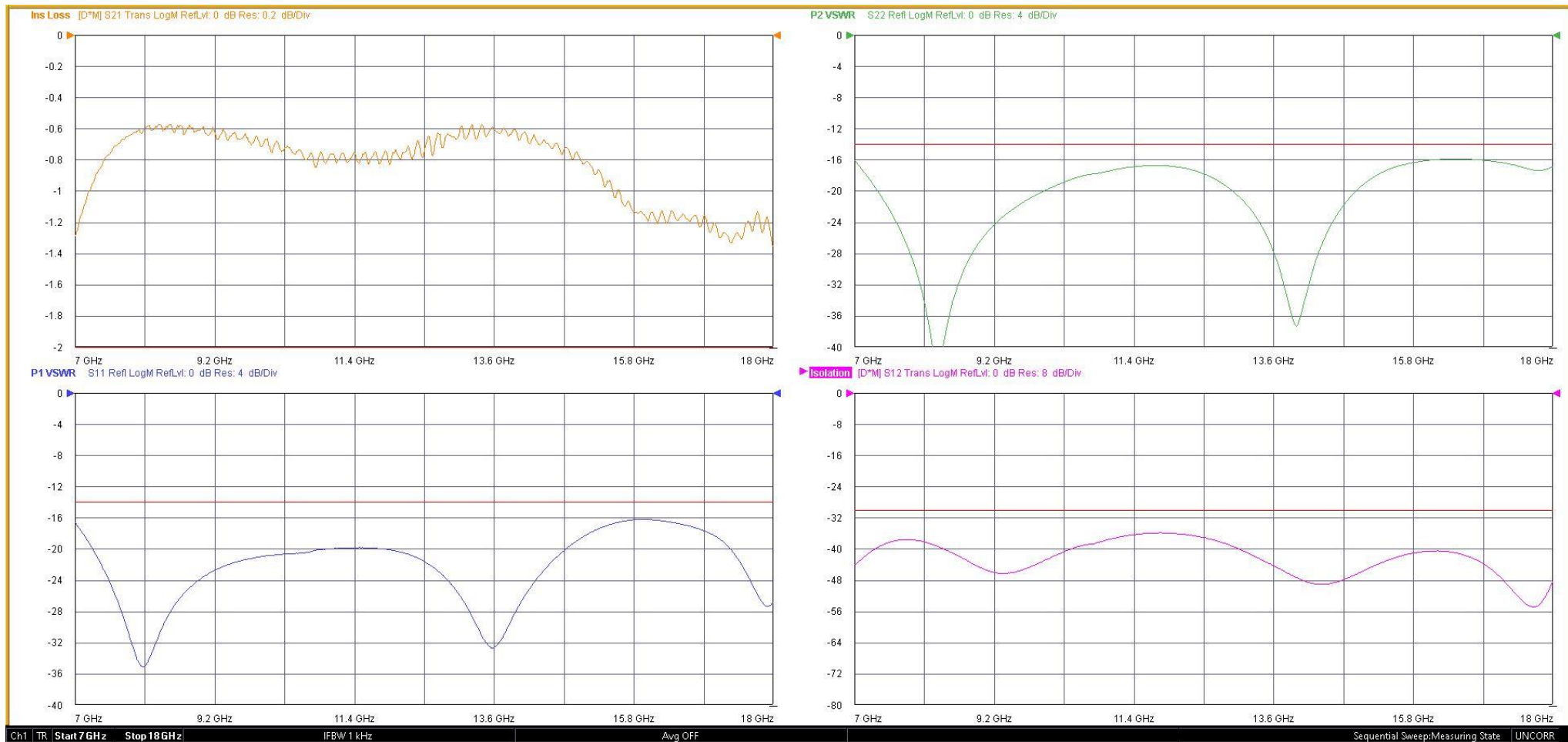

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DiTom:](#)

[D4I7018](#) [D4I7018-1](#) [D4I7018-2](#) [D4I7018-3](#)