

Product data sheet

Characteristics

XCCRAS06U25

shaft coupling - for encoder - homokinetic with bellows Ø 6 mm to 0.25 inch

Product availability: Non-Stock - Not normally stocked in distribution facility



Main

Product or component type	Shaft coupling
Accessory / separate part destination	Rotary encoder with solid shaft
Accessory / separate part category	Coupling accessories
Accessory / separate part type	Homokinetic with bellow
Bore diameter encoder side	0.24 in (6 mm)
Bore diameter machine side	0.25 in

Complementary

Collar material	Aluminium
Bellow material	Stainless steel
Maximum angular misalignment	4°
Maximum axial misalignment	+/- 0.5 mm
Maximum lateral misalignment	+/- 0.3 mm
Torque value	<= 7.08 lbf.in (0.8 N.m)
Product weight	0.04 lb(US) (0.018 kg)

Ordering and shipping details

Category	22486 - SENSORS, PROXIMITY
Discount Schedule	DS2
GTIN	003389110935813
Nbr. of units in pkg.	1
Package weight(Lbs)	4.0000000000000001E-2
Returnability	N
Country of origin	FR


Offer Sustainability

REACH	Reference not containing SVHC above the threshold
California proposition 65	WARNING: This product can expose you to chemicals including:
- - - - - Substance 1	Diisononyl phthalate (DINP), which is known to the State of California to cause cancer, and
- - - - - Substance 2	Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm.
- - - - - More information	For more information go to www.p65warnings.ca.gov

Contractual warranty

Warranty period	18 months
-----------------	-----------

Dimensions

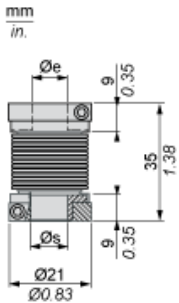

$\varnothing e$	$\varnothing s$
6 mm	6.35 mm

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Telemecanique Sensors:](#)

[XCCRAS06U25](#)