

# XUB9BPANL2

Photoelectric sensors XU, XUB, polarised, Sn 2 m, 12...24 VDC, cable 2 m



## Main

|                               |                                                      |
|-------------------------------|------------------------------------------------------|
| Range of Product              | Telemecanique Photoelectric sensors XU               |
| Series name                   | General purpose single mode                          |
| Electronic sensor type        | Photo-electric sensor                                |
| Sensor name                   | XUB                                                  |
| Sensor design                 | Cylindrical M18                                      |
| Detection system              | Polarised reflex                                     |
| Material                      | Metal                                                |
| Line of sight type            | Axial                                                |
| Type of output signal         | Discrete                                             |
| Supply circuit type           | DC                                                   |
| Wiring Technique              | 3-wire                                               |
| Discrete output type          | PNP                                                  |
| Discrete output function      | 1 NO                                                 |
| Electrical connection         | Cable                                                |
| Cable length                  | 6.56 ft (2 m)                                        |
| Product Specific Application  | -                                                    |
| Emission                      | Red polarised reflex                                 |
| [Sn] nominal sensing distance | 6.56 ft (2 m) polarised reflex need reflector XUZC50 |

## Complementary

|                           |                                                  |
|---------------------------|--------------------------------------------------|
| Enclosure Material        | Nickel Plated Brass                              |
| Lens material             | PMMA                                             |
| Maximum sensing distance  | 9.84 ft (3 m) polarised reflex                   |
| Output Type               | Solid state                                      |
| Add on output             | Without                                          |
| Wire insulation material  | PvR                                              |
| Status LED                | 1 LED yellow)output state                        |
| [Us] rated supply voltage | 12...24 V DC reverse polarity protection         |
| Supply voltage limits     | 10...36 V DC                                     |
| Switching capacity in mA  | <= 100 mA overload and short-circuit protection) |
| Switching frequency       | <= 500 Hz                                        |
| Maximum voltage drop      | <1.5 V closed state)                             |
| Current consumption       | 35 mA no-load                                    |
| Maximum delay first up    | 15 ms                                            |
| Maximum delay response    | 1 ms                                             |
| Maximum delay recovery    | 1 ms                                             |
| Setting-up                | Without sensitivity adjustment                   |
| Diameter                  | 0.71 in (18 mm)                                  |
| Length                    | 2.44 in (62 mm)                                  |
| Net Weight                | 0.11 lb(US) (0.05 kg)                            |

## Environment

|                                       |                                                                      |
|---------------------------------------|----------------------------------------------------------------------|
| Product Certifications                | CE<br>CSA<br>UL                                                      |
| Ambient air temperature for operation | -13...131 °F (-25...55 °C)                                           |
| Ambient Air Temperature for Storage   | -40...158 °F (-40...70 °C)                                           |
| Vibration resistance                  | 7 gn +/- 1.5 mm 10...55 Hz) IEC 60068-2-6                            |
| Shock resistance                      | 30 gn 11 ms) IEC 60068-2-27                                          |
| IP degree of protection               | IP67 double insulation IEC 60529<br>IP65 double insulation IEC 60529 |

## Ordering and shipping details

|                   |                                     |
|-------------------|-------------------------------------|
| Category          | 22415-SENSORS, PHOTOELECTRIC, BASIC |
| Discount Schedule | DS2                                 |
| GTIN              | 3389110159318                       |
| Returnability     | No                                  |
| Country of origin | FR                                  |

## Packing Units

|                              |                       |
|------------------------------|-----------------------|
| Unit Type of Package 1       | PCE                   |
| Number of Units in Package 1 | 1                     |
| Package 1 Height             | 1.65 in (4.2 cm)      |
| Package 1 Width              | 3.74 in (9.5 cm)      |
| Package 1 Length             | 5.12 in (13.0 cm)     |
| Package 1 Weight             | 3.88 oz (110.0 g)     |
| Unit Type of Package 2       | S02                   |
| Number of Units in Package 2 | 22                    |
| Package 2 Height             | 5.91 in (15.0 cm)     |
| Package 2 Width              | 11.81 in (30.0 cm)    |
| Package 2 Length             | 15.75 in (40.0 cm)    |
| Package 2 Weight             | 6.00 lb(US) (2.72 kg) |

## Offer Sustainability

|                            |                                                                                                                                                                                                                                                                                                                                                                                   |
|----------------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Sustainable offer status   | Green Premium product                                                                                                                                                                                                                                                                                                                                                             |
| California proposition 65  | WARNING: This product can expose you to chemicals including: Diisononyl phthalate (DINP), which is known to the State of California to cause cancer, and Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a> |
| REACH Regulation           | <a href="#">REACH Declaration</a>                                                                                                                                                                                                                                                                                                                                                 |
| EU RoHS Directive          | Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>                                                                                                                                                                                                                                                                                    |
| Mercury free               | Yes                                                                                                                                                                                                                                                                                                                                                                               |
| RoHS exemption information | <a href="#">Yes</a>                                                                                                                                                                                                                                                                                                                                                               |
| Environmental Disclosure   | <a href="#">Product Environmental Profile</a>                                                                                                                                                                                                                                                                                                                                     |
| Circularity Profile        | <a href="#">End Of Life Information</a>                                                                                                                                                                                                                                                                                                                                           |


## Contractual warranty

|          |           |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|

---

Dimensions

---

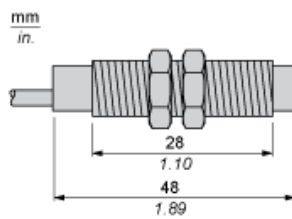


---

## Wiring Schemes

---

### PNP Outputs

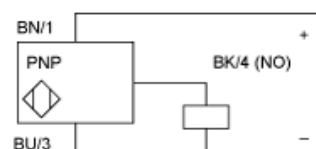


BN : Brown  
BU : Blue  
BK : Black

---

Detection Curves

---

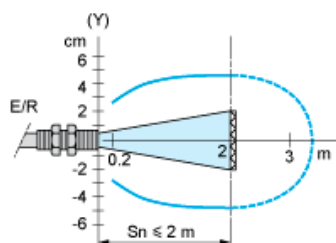

(Y) Ø of beam  
With reflector XUZY50

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Telemecanique Sensors:](#)

[XUB9BPANL2](#)