



## Main

|                                    |                   |
|------------------------------------|-------------------|
| Accessory / separate part category | Cabling accessory |
| Accessory / Separate Part Type     | Jumper cable      |

## Complementary

|                                     |                                   |
|-------------------------------------|-----------------------------------|
| Jumper cable end 1                  | M12 male 3 pins straight screw-on |
| Jumper cable end 2                  | M8 female 3 pins elbowed screw-on |
| Cable composition                   | 3 x 0.34 mm <sup>2</sup>          |
| Cable length                        | 6.56 ft (2 m)                     |
| Wire insulation material            | PUR                               |
| Cable outer diameter                | 0.20 in (5.2 mm)                  |
| [Ue] rated operational voltage      | 60 V AC<br>75 V DC                |
| Line Rated Current                  | 4 A                               |
| Insulation resistance               | >= 1000 MOhm                      |
| Maximum resistance across terminals | 5000 mOhm                         |
| Net Weight                          | 0.18 lb(US) (0.08 kg)             |

## Environment

|                                       |                                                                       |
|---------------------------------------|-----------------------------------------------------------------------|
| IP Degree of Protection               | IP69K<br>IP65<br>IP67                                                 |
| Product Certifications                | cULus                                                                 |
| Ambient air temperature for operation | -31...194 °F (-35...90 °C) static<br>23...194 °F (-5...90 °C) flexing |
| Ambient Air Temperature for Storage   | -31...212 °F (-35...100 °C)                                           |

## Ordering and shipping details

|                       |                      |
|-----------------------|----------------------|
| Category              | 22483-MACHINE CABLES |
| Discount Schedule     | DS3                  |
| GTIN                  | 3389110762679        |
| Nbr. of units in pkg. | 1                    |
| Package weight(Lbs)   | 3.42 oz (97.0 g)     |
| Returnability         | No                   |
| Country of origin     | CZ                   |

## Packing Units

|                              |                        |
|------------------------------|------------------------|
| Unit Type of Package 1       | PCE                    |
| Package 1 Height             | 0.39 in (1 cm)         |
| Package 1 width              | 7.09 in (18 cm)        |
| Package 1 Length             | 7.87 in (20 cm)        |
| Unit Type of Package 2       | S02                    |
| Number of Units in Package 2 | 40                     |
| Package 2 Weight             | 9.50 lb(US) (4.309 kg) |
| Package 2 Height             | 5.91 in (15 cm)        |
| Package 2 width              | 11.81 in (30 cm)       |
| Package 2 Length             | 15.75 in (40 cm)       |


## Offer Sustainability

|                            |                                                                                                                                                                                                                                                                                                                                                                                   |
|----------------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Sustainable offer status   | Green Premium product                                                                                                                                                                                                                                                                                                                                                             |
| California proposition 65  | WARNING: This product can expose you to chemicals including: Diisononyl phthalate (DINP), which is known to the State of California to cause cancer, and Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a> |
| REACH Regulation           | <a href="#">REACH Declaration</a>                                                                                                                                                                                                                                                                                                                                                 |
| EU RoHS Directive          | Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>                                                                                                                                                                                                                                                                                    |
| Mercury free               | Yes                                                                                                                                                                                                                                                                                                                                                                               |
| RoHS exemption information | <a href="#">Yes</a>                                                                                                                                                                                                                                                                                                                                                               |
| Environmental Disclosure   | <a href="#">Product Environmental Profile</a>                                                                                                                                                                                                                                                                                                                                     |
| Circularity Profile        | <a href="#">End Of Life Information</a>                                                                                                                                                                                                                                                                                                                                           |

## Contractual warranty

|          |           |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|

## Dimensions

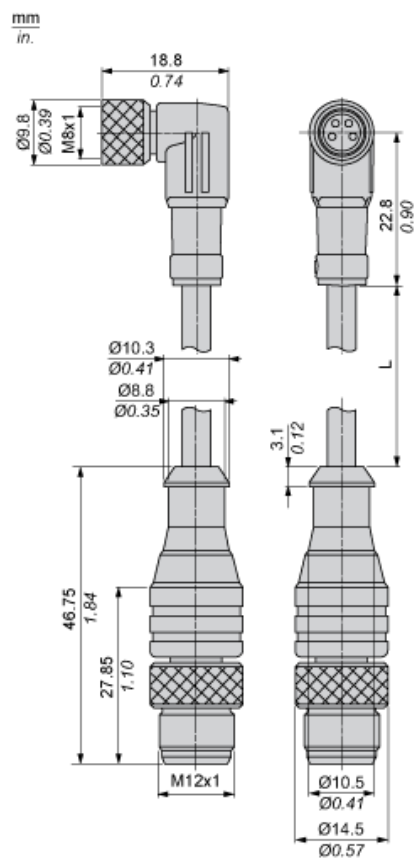


L : Length of cable

---

Connections and Schemes

---

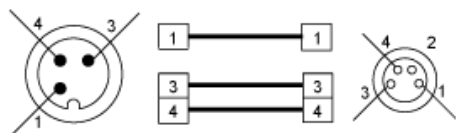

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Telemecanique Sensors:](#)

[XZCR1510040H2](#)