




Models 6747, 6748
BNC (F) PCB Mount Straight, Right Angle – 75 Ω

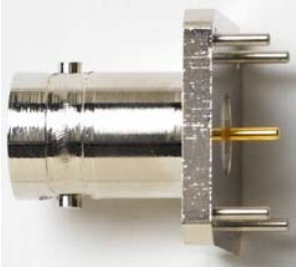

Model 6747 BNC (F) PCB Mount Straight

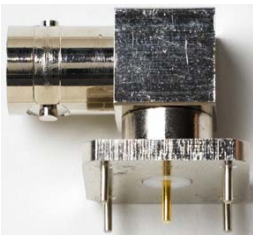

Model 6748 BNC (F) PCB Mount Right Angle

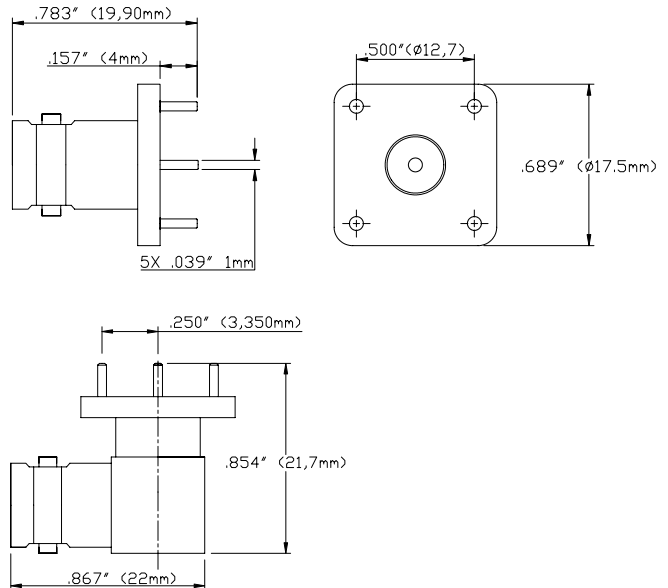

Use Pomona
PCB mount BNC's for secure
board attachment

Features

- PCB straight mount design or right angle mount design.
- Precision machined. Gold plated contacts. PTFE (**not delrin**).

Materials

- Body and PCB mount pins made from precision machined high quality brass (not die cast).
- Female center contacts are gold plated heat-treated beryllium copper.
- Pin Socket is gold over copper alloy.

Ordering Information

Model: 6747 BNC (F) PCB Mount Straight,
6748 BNC (F) PCB Mount Right Angle.

Specifications

Nominal impedance	75 Ω
Frequency	0-3 GHz
VSWR	1.10 max. 0-1 GHz 1.35 max. 1-3 GHz
Center contact resistance	1.5 mΩ
Insulation resistance	5000 MΩ
Number of insertions (BNC)	500
Ratings: Voltage: 500 Vrms Operating temperature: -85 °F to +131 °F (-65 °C to +155 °C) Max.	

USA: Sales: 800-490-2361 Technical Support: 800-241-2060 Fax: 888-403-3360

Europe: 31-(0) 40 2675 150 International: 425-446-5500

e-mail: technicalsupport@pomonatest.com

Where to Buy: www.pomonaelectronics.com

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Pomona:](#)

[6748](#) [6747](#)