


**Models 6883, 6884
Dual Binding Posts with Base (raised base)**



Model 6883 Dual Binding Posts



Model 6884 Dual Binding Posts with Raised Base

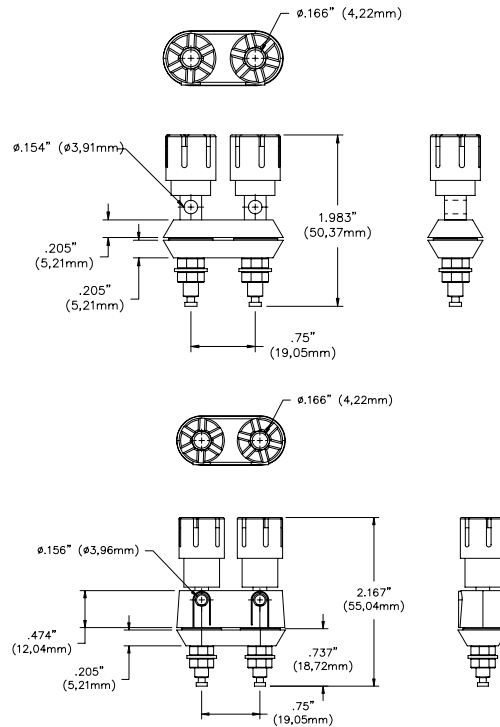

Use as an ideal interconnect

Features

- 5-way binding post with 0.154" cross-hole that accepts up to 12 AWG wire and standard banana plugs.
- Posts are spaced at the standard 3/4" inch spacing to mate to dual banana plugs.
- 30 A current rating.

Materials

- Posts are made of nickel-plated brass.
- Insulators and base are made of nylon.

Ordering Information

Model: 6883, 6884

USA: Sales: 800-490-2361 Technical Support: 800-241-2060 Fax: 888-403-3360

Europe: 31-(0) 40 2675 150 **International:** 425-446-5500

e-mail: technicalsupport@pomonatest.com

Where to Buy: www.pomonaelectronics.com

Specifications

Current rating	30 A at low voltage
Voltage rating	500 V dc at low current
Wire gauge	Up to 12 AWG
Operating temperature	Up to 70 °C

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Pomona:](#)

[6884](#) [6883](#)