


Model 5699, 5700 & 5701 Terminal Strip Banana Jack Adapter, 6-32, 8-32 & 10-32 Threaded Stud

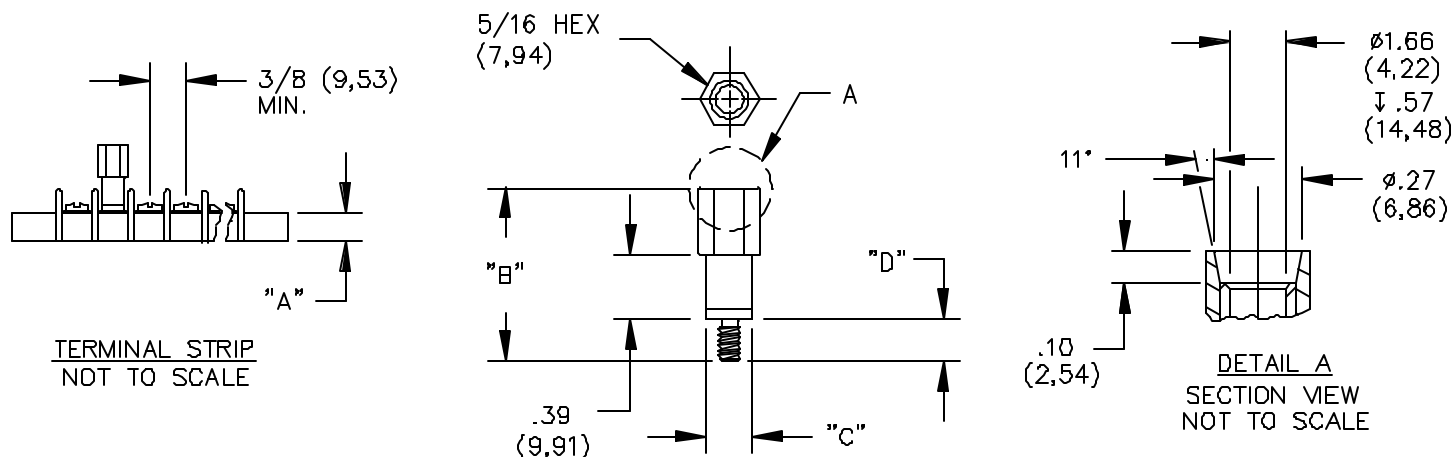

Model	Dim "A"	Dim "B"	Dim "C"	Dim "D"
5699	.35 min (8,89)	1.04 (26,42)	Ø .28 (7,11)	.25 (6,35)
5700	.44 min (11,18)	1.13 (28,70)	Ø .38 (9,65)	.32 (8,13)
5701	.50 min (12,70)	1.13 (28,70)	Ø .38 (9,65)	.32 (8,13)

FEATURES:

- This adapter provides a banana jack connection by replacing the screw in a terminal strip.
- Secure connections can be made with standard banana plug patch cords without breaking the connection to the terminal strip.
- Banana jack .166 dia.

MATERIALS:

Banana Jack with 6-32 (Model 5699) Binding Head, threaded stud – Brass, Alloy 360, ½ Hard
8-32 (Model 5700)
10-32 (Model 5701)

Electroless nickel plate per MIL-C-26074, Class 1 200/300 microinches

Insulation – Nylon 6, 20% glass filled

RATINGS:

Operating Temperature: +102°C. (+216°F.) Max.

Operating Voltage: 1100 VRMS Max. (Model 5699)

1600 VRMS Max (Model 5700)

1700 VRMS Max. (Model 5701)

Current: 25 Amperes Max.

Power: 7500 Watts Max.

ORDERING INFORMATION: Model 5699-*

*=Color Code, -0 Black, -2 Red, -3 Orange, -4 Yellow, -5 Green, -6 Blue, -9 White

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm).

All specifications are to the latest revisions. Specifications are subject to change without notice.

Registered trademarks are the property of their respective companies. Made in USA

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

5699-0#