


Models 72905
Clip lead for Micro SMD Grabber

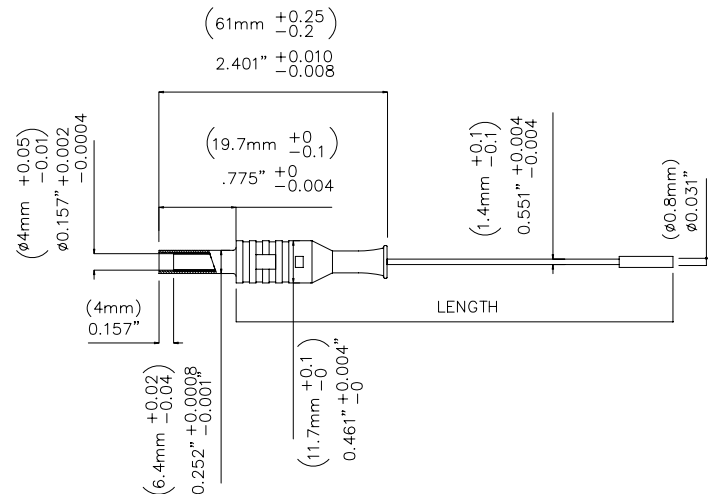

**Attach your Micro SMD
Grabber to Standard test
leads.**

Features

- Clip lead for easy attachment of Micro SMD Grabbers Pomona 72902 and 72906 to standard test leads
- 0.8mm female/4mm female

Materials

- Connector Body is Nickel plated Brass.
- Connector insulation is Polypropylene
- 0.8mm Socket is Gold over Nickel plated Brass.
- Insulation of 0.8mm is Elastomere
- Wire is Silicone.

Ordering Information

Model: 72905-Color
Available colors: Black (-0), Red (-2)

USA: Sales: 800-490-2361 Technical Support: 800-241-2060 Fax: 888-403-3360

Europe: 31-(0) 40 2675 150 **International:** 425-446-5500

e-mail: technicalsupport@pomonatest.com

Where to Buy: www.pomonaelectronics.com

Specifications

Max Current	Max. 2A
Max Voltage	33 V AC / 70 V DC
Temperature Range	-20° C + 80° C
Max Resistance	Less than 8 mΩ

Rating: *hands free testing* in controlled environment: 70Vrms max. For CE compliance: Not intended for hand-held use at voltages above 33Vrms/70Vdc

All dimensions are in inches. Tolerances (except noted): .xx = $\pm 0.02''$ (.51 mm), .xxx = $\pm 0.005''$ (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

72905-0 72905-2