

Models 72923

SMD Test Probe W/ Sharp, Spring Mounted Tip, 2MM



Features

- **SMD test probe with sharp, spring mounted tip and 2mm jack**
- Provides ultra-fine control for probing high density SMD circuits
- Very fine 0.03in (0.7mm) diameter stainless steel tip is spring-mounted for controlled pressure
- Removable, clear IC insulator cap prevents shorting of adjacent IC logos.
- Sheathed 2mm receptacle adapts to 2mm test leads and adapters.


Materials

- Probe Body: Brass
- Probe Tip: Steel
- Insulation: Polypropylene
- Cap Insulation: Polypropylene

Ordering Information

Model:72923-Color

Available colors: Black (-0), or Red (-2)

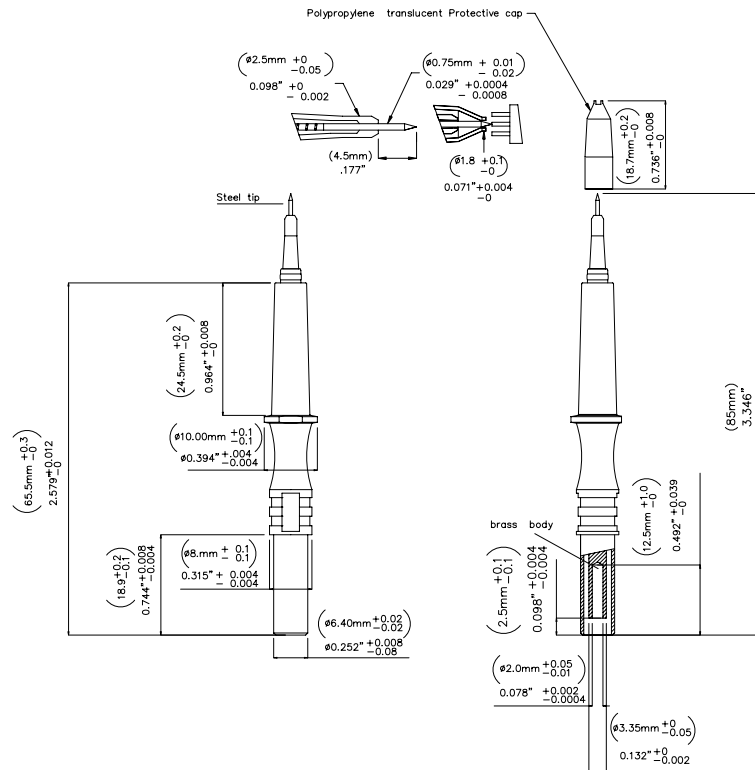

Specifications

Max Current	Max. 1A
Max Voltage	600 V Cat III
Temperature	-20° C + 80° C
Max Resistance	Less than 5 mΩ

USA: Sales: 800-490-2361 Technical Support: 800-241-2060 Fax: 888-403-3360

Europe: 31-(0) 40 2675 150 **International:** 425-446-5500

e-mail: technicalsupport@pomonatest.com

Where to Buy: www.pomonaelectronics.com

All dimensions are in inches. Tolerances (except noted): .xx = $\pm .02"$ (.51 mm), .xxx = $\pm .005"$ (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

72923-2 72923-0