

Models 72924
Mini-alligator Clip with 2mm Jack



Features


- Mini-alligator clip with 2mm jack, (Black)
- Rating: 600V Cat II, 10A

Materials

- Insulation: Polypropylene
- Jaws: Nickel Plated Steel

Ordering Information

Model: 72924-Color
Available colors: Black (-0), Red (-2)

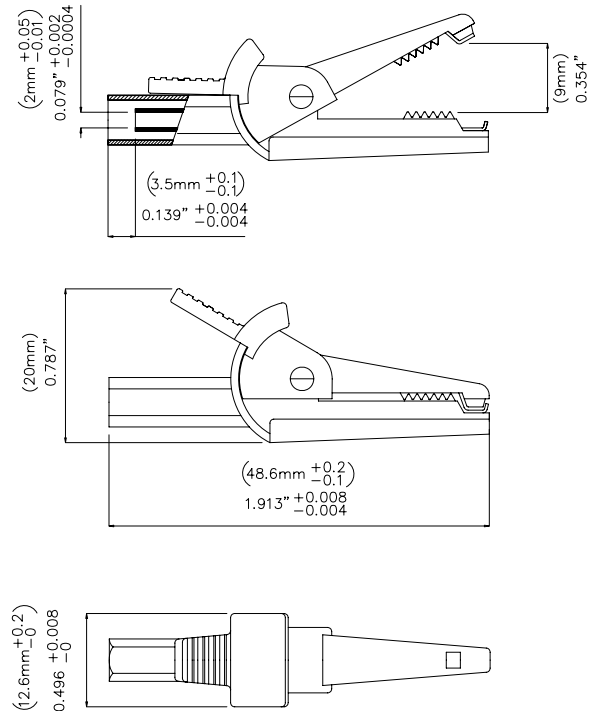

Specifications:

Max Current	Max. 10A
Max Voltage	600 V Cat III
Max Resistance	Less than 15 mΩ

USA: Sales: 800-490-2361 Technical Support: 800-241-2060 Fax: 888-403-3360

Europe: 31-(0) 40 2675 150 **International:** 425-446-5500

e-mail: technicalsupport@pomonatest.com

Where to Buy: www.pomonaelectronics.com

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

[72924-2](#) [72924-0](#)