


**Models 72929**  
**Mini SMD Grabber Test Clip Lead with 4mm Jack**

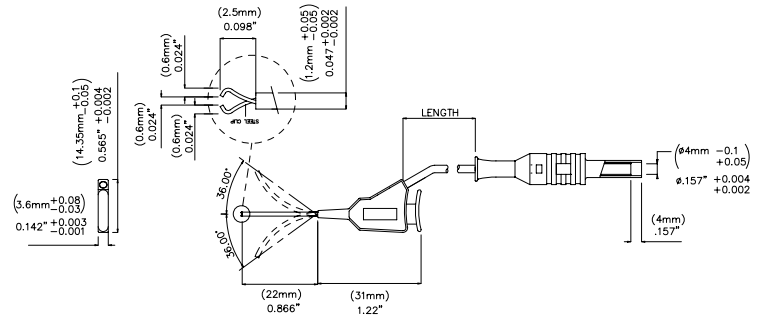

**Features**

- SMD Grabber Test Clip (Pomona 72906) with 20 Inch(50cm) lead
- 4mm Jack for easy attachment to DMM leads.

**Materials**

Grabber End:

- Insulation: Polyamide
- Jaws: Steel

Jack End:

- Insulation: Polypropylene
- Socket Body: Nickel plated Brass

**Ordering Information**

Model: 72929-20-Color  
Black (-0) or Red (-2)

**Specifications**

Max Current Admissible	1A
Voltage; Max - Tension	33 V AC / 70 V DC

**Rating:** *hands free testing* in controlled environment: 70Vrms max. For CE compliance: Not intended for hand-held use at voltages above 33Vrms/70Vdc

**USA:** Sales: 800-490-2361 Technical Support: 800-241-2060 Fax: 888-403-3360

**Europe:** 31-(0) 40 2675 150 **International:** 425-446-5500

**e-mail:** [technicalsupport@pomonatest.com](mailto:technicalsupport@pomonatest.com)

**Where to Buy:** [www.pomonaelectronics.com](http://www.pomonaelectronics.com)

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

[72929-20-0](#) [72929-20-2](#)