


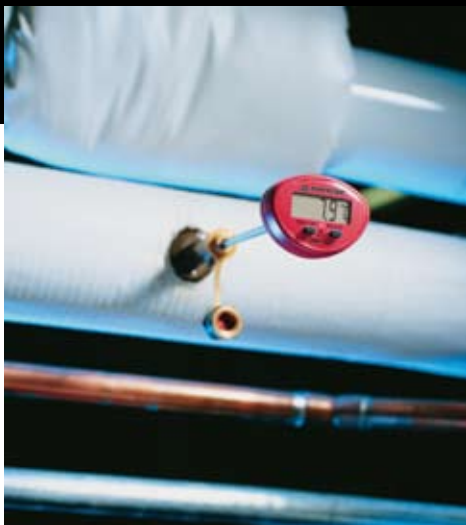

TPP1-C1, TPP1-F1 Immersion Probe

Pocket thermometer probe

Small and portable for those measurements out in the field. Digital displays with 0.1 ° resolution. Fahrenheit and Celsius versions available. Flat surface mount thermometer also available.

- 0.1 ° resolution
- Temperature
 - 50 °C to 250 °C (TPP1-C1)
 - 58 °F to 480 °F (TPP1-F1)
- Easy to read digital display (3½ digits)
- Data hold
- Protective sleeve cover with pocket clip
- Immersion or piercing
- Compact and portable
- Long battery life 200 hours, typical
- Battery included

**TPP1-C1****TPP1-F1**

No hassle warranty

No waiting.

No shipping charges.



Our commitment to high-quality products and customer service is demonstrated by our industry exclusive "No Hassle" warranty. In the unlikely event that an Amprobe Test Tool requires warranty service, any of our local dealers are authorized to replace it, on the spot.

(note: \$500 MSLP limit)



TPP1-C1, TPP1-F1 Immersion Probe

Data Sheet

General Specifications

Working Temperature	0 °C to 50 °C at <80 % relative humidity
Storage Temperature	0 °C to 60 °C (32 °F to 122 °F) at RH <80 %
Power Supply 3 V battery,	CR 2032, coin cell
Battery Life	approximately 200 hours
Pollution Degree	IP40
Altitude	2000 m (6561 ft)
Dimensions	40 mm x 30 mm x 160 mm (1.57 in x 1.18 in x 6.29 in)
Weight	approximately 16 g (.56 oz) including battery

Specifications (23 °C ± 5°, <70 % RH)

Function	Range	Resolution	Accuracy
Display	LCD, 3-1/2 digit		
Overload Display	OL or -OL		
Range	-50 °C to 250 °C (-58 to 482 °F)		
	-50 °C to -20 °C	1.0 °C	±3 °C
	-19.9 °C to 49.9 °C	0.1 °C	±2 °C
	50 °C to 199.9 °C	0.1 °C	± (2 % rdg +1 °C)
	200 °C to 250 °C	1.0 °C	± (2 % rdg +1 °C)
	-58 °F to -4 °F	1.0 °F	± 5 °F
	-3.8 °F to 121.8 °F	1.0 °F	± 1.8 °F
	122 °F to 391 °F	0.1 °F/1 °F	± (2 % rdg + 1.8 °F)
	392 °F to 482 °F	1 °F	± (2 % rdg + 2 °F)
Temperature Change/response time	> 10 °K/s		
Temperature Coefficient	<0.1 multiply with tolerance per °C for environment condition 0° to 18 °C and 28 °C to 50 °C		

Amprobe® Test Tools
website: www.Amprobe.com
email: info@amprobe.com
Everett, WA 98203
Tel: 877-AMPROBE

Amprobe® Test Tools Europe
In den Engematten 14
79286 Glottertal, Germany
Tel.: +49 (0) 7684 8009 - 0

©2007 Amprobe Test Tools. All rights reserved.
4/2007 2140063 D-US-N Rev C

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AMPROBE:](#)

[TPP1-C1](#)