


## Model 1126 Multi-Stacking Banana Plug To Stacking Pin Tip Plug

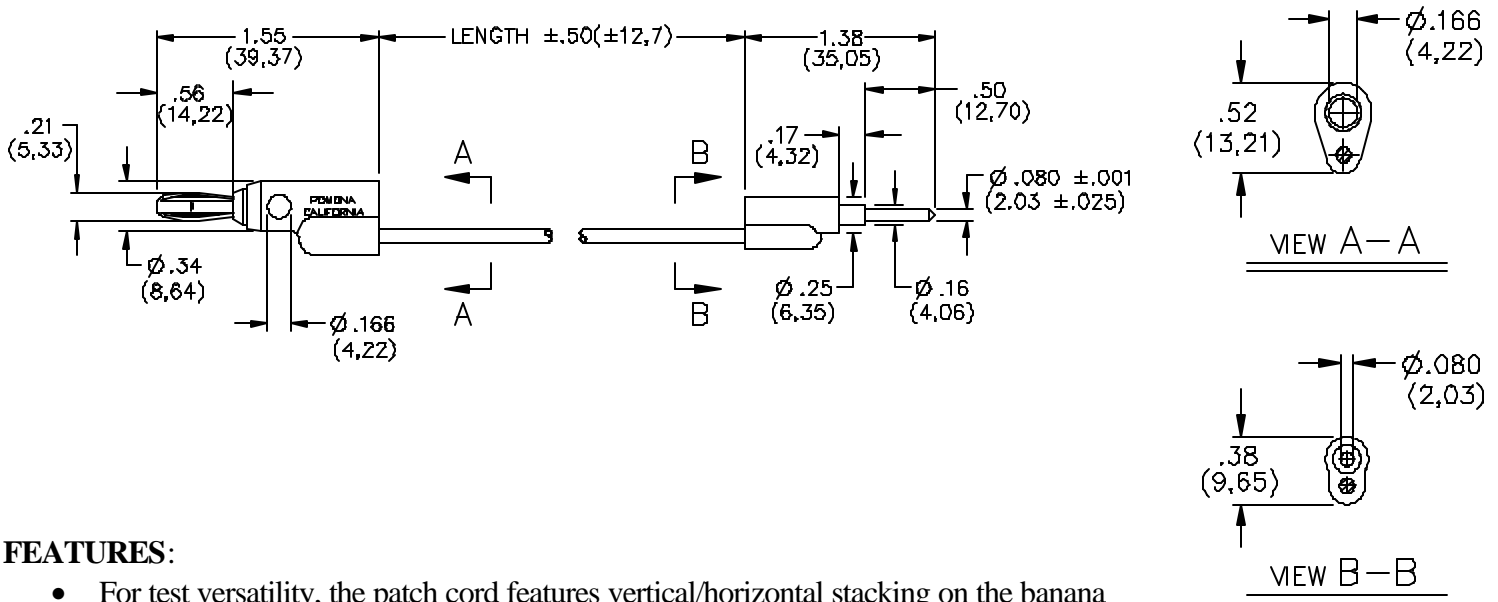

### FEATURES:

- For test versatility, the patch cord features vertical/horizontal stacking on the banana plug and vertical stacking on the pin tip side.
- Patch cord converts a pin tip jack to a banana plug or a banana jack to a pin tip plug.
- Banana and Pin Tip Plugs are molded directly to the wire for long life.

### MATERIAL:

Banana Plug: Spring – Beryllium Copper, Nickel Plated

Body: Brass, Nickel Plated

Insulation: Polypropylene, Color matches wire

Wire: 20 AWG, Stranding 41 x 36 Tinned Copper, PVC Insulated, .087" (2.21mm) O.D.

Color per part number. Marking: MODEL 1126-\*

Pin Tip Plug: Body – Brass, Gold Plated

Stackup Spring: Beryllium Copper, Gold Plated

Insulation: Polypropylene, Color matches wire

### RATINGS:

Voltage: Hand-held Testing: 30VAC/60VDC MAX.

Hands Free Testing in Controlled Voltage environments: 3000 WVDC

Operating Temperature: +55°C (+131°F)

Current: 5 Amperes Max.

### ORDERING INFORMATION: Model 1126-X-\*

X = Length, Standard Lengths: 4" (10,16cm), 8" (20,32cm), 12" (30,48cm), 18" (45,72cm), 24" (60,96cm), 36" (91,44cm), 48" (121,92), & 60" (152,40cm). Custom lengths can be quoted upon request.

\* = Color, -0 Black, -2 Red. Ordering Example: 1126-24-2 Patch cord will be 24" (60,96cm), color red.

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm).

All specifications are to the latest revisions. Specifications are subject to change without notice.

Registered trademarks are the property of their respective companies.

Made in USA

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

[1126-18-0](#) [1126-18-2](#) [1126-24-0](#) [1126-24-2](#) [1126-36-0](#) [1126-36-2](#) [1126-12-2](#) [1126-12-0](#) [1126-60-0](#) [1126-60-2](#)  
[1126-48-2](#) [1126-48-0](#) [1126-4-0](#) [1126-4-2](#) [1126-8-0](#) [1126-8-2](#)