


Model 1368 Double Banana Plug To Single Banana Plug Breakouts

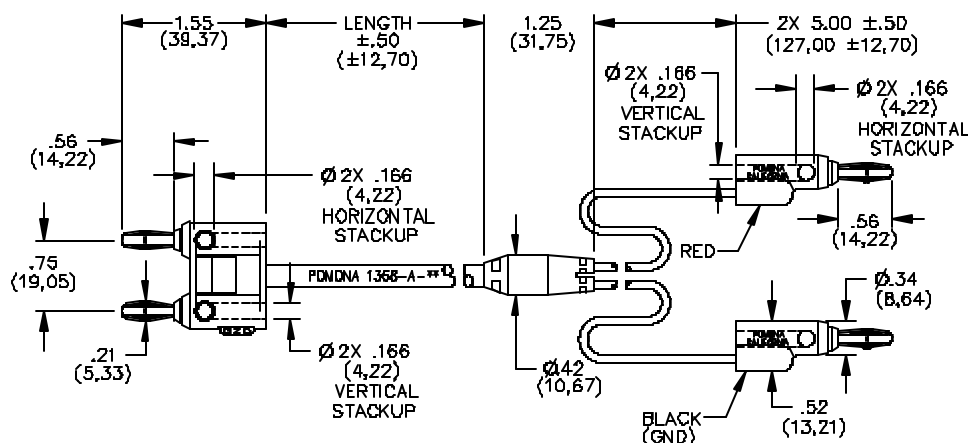

FEATURES:

- Ideal for Connecting Power Supply or Test Equipment to Bread Boards
- Double Banana Plugs Mates to Pomona Models 2269, 5233 and 4243.
- Single Banana Plugs Mate to Pomona Model Numbers 1581, 2854, 4900 and 3760.

MATERIALS:

Banana Plugs:

Plug Body: Brass, Nickel Plated

Spring: Beryllium Copper, Nickel Plated

Insulation: Polypropylene Molded to the Plug Bodies and Cable, Color: Gray

Marking: POMONA ELECTRONICS CO. INC. POMONA CALIFORNIA

Cable: 18 AWG, Stranding 65 x 36 t.c., PVC Insulated, .250" (6.35 mm) O.D., 2 conductor twisted pair

Marking: Pomona 1368-A-*

Color: Gray

Molded Breakout:

PVC Molded to the Breakout Leads and Cable. Color: Gray

Breakout Leads:

20 AWG, Stranding 41 x 36 t.c., PVC Insulated, .087" (2.21 mm) O.D.

Colors: One Red, One Black

RATINGS:

Operating Temperature: +50°C Max.

Operating Voltage: 300 VRMS.

ORDERING INFORMATION: Model 1368-A-XX

XX = Wire Length, Standard Lengths: 18" (457,2cm), 24" (60,96cm), 30" (762,0cm), 36" (91,44cm), 48" (121,92cm), 60" (152,4cm). Additional lengths can be quoted upon request.

* = Color, -0 Black, -2 Red. Ordering Example: 1368-A-24 Cable assembly is 24" (60,96cm)

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm).

All specifications are to the latest revisions. Specifications are subject to change without notice.

Registered trademarks are the property of their respective companies. Made in USA

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

[1368-A-60](#) [1368-A-48](#) [1368-A-24](#) [1368-A-36](#) [1368-A-18](#)