


## Model 1368 Double Banana Plug To Single Banana Plug Breakouts

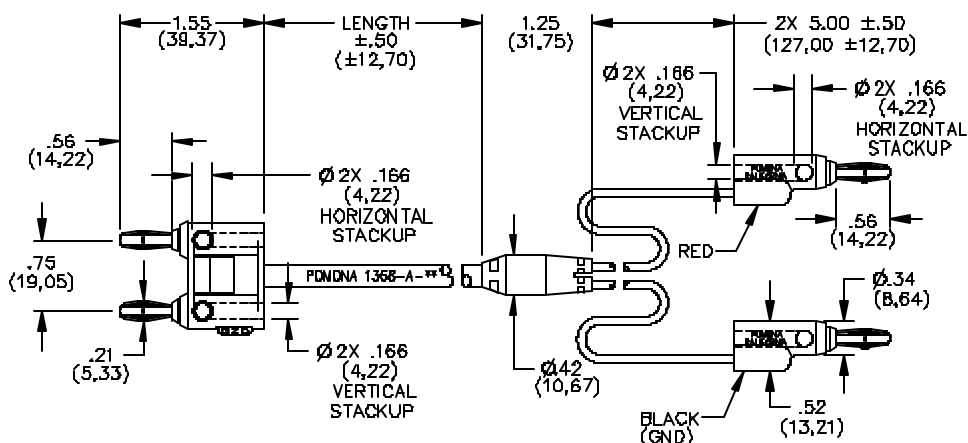

### FEATURES:

- Ideal for Connecting Power Supply or Test Equipment to Bread Boards
- Double Banana Plugs Mates to Pomona Models 2269, 5233 and 4243.
- Single Banana Plugs Mate to Pomona Model Numbers 1581, 2854, 4900 and 3760.

### MATERIALS:

#### Banana Plugs:

Plug Body: Brass, Nickel Plated

Spring: Beryllium Copper, Nickel Plated

Insulation: Polypropylene Molded to the Plug Bodies and Cable, Color: Gray

Marking: POMONA ELECTRONICS CO. INC. POMONA CALIFORNIA

Cable: 18 AWG, Stranding 65 x 36 t.c., PVC Insulated, .250" (6,35 mm) O.D., 2 conductor twisted pair

Marking: Pomona 1368-A-\*

Color: Gray

#### Molded Breakout:

PVC Molded to the Breakout Leads and Cable. Color: Gray

#### Breakout Leads:

20 AWG, Stranding 41 x 36 t.c., PVC Insulated, .087" (2,21 mm) O.D.

Colors: One Red, One Black

### RATINGS:

Operating Temperature: +50°C Max.

Operating Voltage: 300 VRMS.

### ORDERING INFORMATION: Model 1368-A-XX

XX = Wire Length, Standard Lengths: 18" (457,2cm), 24" (60,96cm), 30" (762,0cm),

36" (91,44cm), 48" (121,92cm), 60" (152,4cm). Additional lengths can be quoted upon request.

\* = Color, -0 Black, -2 Red. Ordering Example: 1368-A-24 Cable assembly is 24" (60,96cm)

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ± .005" (.127 mm).

All specifications are to the latest revisions. Specifications are subject to change without notice.

Registered trademarks are the property of their respective companies. Made in USA

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

[1368-A-60](#) [1368-A-48](#) [1368-A-24](#) [1368-A-36](#) [1368-A-18](#)