


### Model 2142

### Insulated Miniature Banana Jack

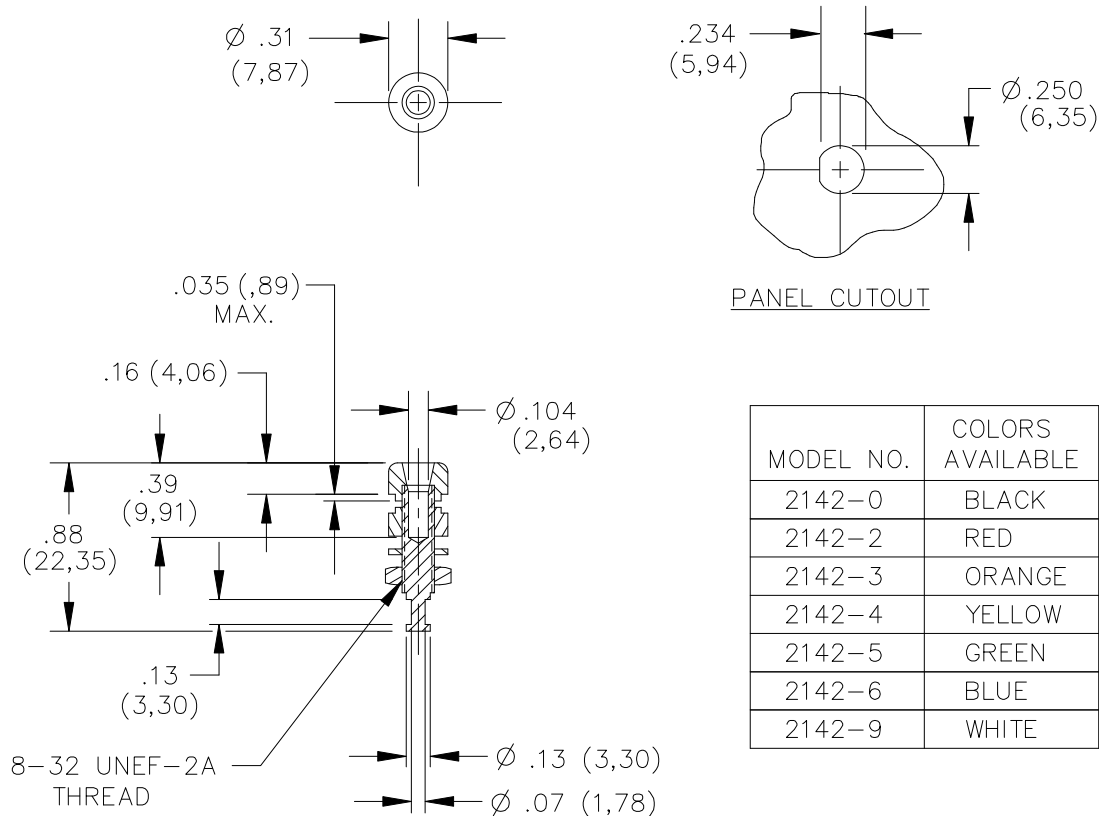

#### FEATURES:

- Accepts miniature banana plugs.
- Mounts in panels up to .250" thick.

#### MATERIAL:

Banana Jack Insulation – Polycarbonate. Color: Black

Panel Insulator – Polycarbonate. Color: Black

Lockwasher, #8 Internal Tooth – Steel

Hex Nut, #8-32 – Brass

Banana Jack Body – Brass

#### Finish:

Lockwasher #8 – Nickel plated

Hex Nut - Nickel plated.

Banana Jack Body - Gold plated.

#### RATINGS:

Operating Temperature: +115°C (+239°F) Max.

Current: 5 Amperes.

#### ORDERING INFORMATION: Model 2142-\*

\*=Color Code – See Tabulation Block

Sold in packages of 10.

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm).

All specifications are to the latest revisions. Specifications are subject to change without notice.

Registered trademarks are the property of their respective companies.

USA: Sales: 800-490-2361

Fax: 425-446-5844

Technical Support: [technicalsupport@pomonatest.com](mailto:technicalsupport@pomonatest.com)

Europe: 31-(0) 40 2675 150

International: 425-446-5500

Where to Buy: [www.pomonaelectronics.com](http://www.pomonaelectronics.com)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

[2142-0](#) [2142-4](#) [2142-2](#) [2142-3](#) [2142-6](#) [2142-9](#) [2142-5](#) [2142-2#](#) [2142-0#](#) [2142-5#](#) [2142-4#](#) [2142-6#](#) [2142-9#](#)