


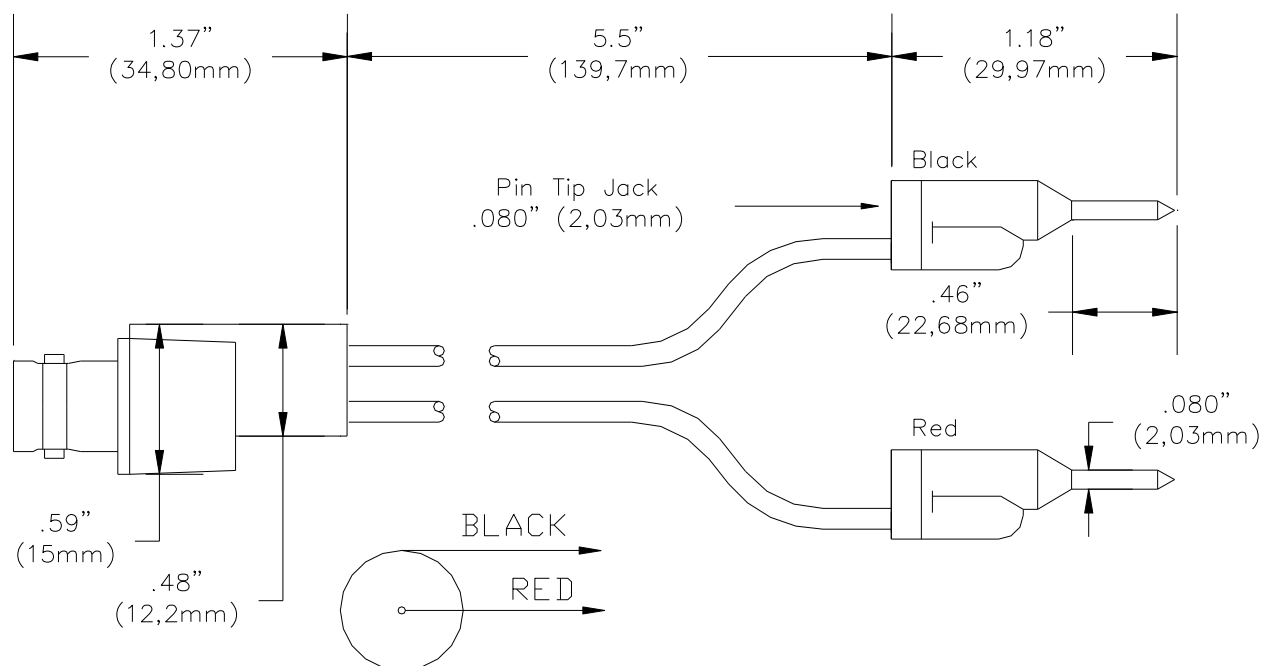

SCHEMATIC

FEATURES:

- ✓ Converts BNC (male) cables / connectors to stackable pin tip for test versatility.
- ✓ Miniature banana plug springs are gold plated Beryllium Copper for excellent electrical connection.
- ✓ BNC connector is molded directly to the wire for pull strength durability and dust and moisture resistance.
- ✓ Black wire is connected to BNC shell, red wire to BNC center contact.
- ✓ Pin tip plugs are stackable.

MATERIALS:

BNC: Nickel Plated Brass, Center Contact: Gold Plated Beryllium Copper

Dielectric: PTFE

Wire: 20 AWG, PVC Insulated

Pin Tip: Brass Gold Plated, Spring: Beryllium Copper, Gold Plated

Insulation: Polypropylene plug color matches color of wire.

RATINGS:

Voltage: Hands free testing in controlled voltage environments: 500 Vrms Max. *For CE compliance:* not intended for hand-held use at voltages above 33 Vrms/70 Vdc.

Operating Temperature: +131°F (+55°C) Max.

ORDERING INFORMATION: Model 3221*

* Custom lengths are available, contact Pomona Technical Support: 800-241-2060 (technicalsupport@pomonatest.com)

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm).

All specifications are to the latest revisions. Specifications are subject to change without notice.

Registered trademarks are the property of their respective companies.

Sales: 800-490-2361 Fax: 888-403-3360 Technical Support: 800-241-2060 (technicalsupport@pomonatest.com)

For "Where to Buy" information, visit the Pomona web site at www.pomonaelectronics.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

3221 3221#