


Model 3276 & 4513
Miniature Banana Plug with Threaded Stud

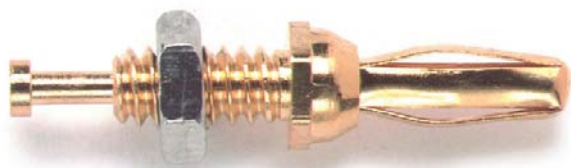

| Model | "X" Dimension |
|-------------|---------------|
| 3276 | .23" (5,8mm) |
| 4513 | .48" (12,2mm) |

Minimum Panel Thickness is 0.030" (0.76mm)

Features

- Threaded stud enables fast and easy mounting to panels.
- Solder turret allows wire attachment.
- Miniature banana plug features gold plated Beryllium Copper for long insertion life and low contact resistance.

Materials



Miniature Banana Plug:
 Spring: Beryllium Copper, Gold Plated
 Body: Brass, Gold Plated
 Hex Nut: 4-40 Nut, Brass, Nickel Plated

Ratings

Operating Voltage: 2500 VDC
 Current: 5 Amperes Max.

Ordering Information

Model 3276
 Model 4513
 Parts are packaged ten per bag, unassembled.

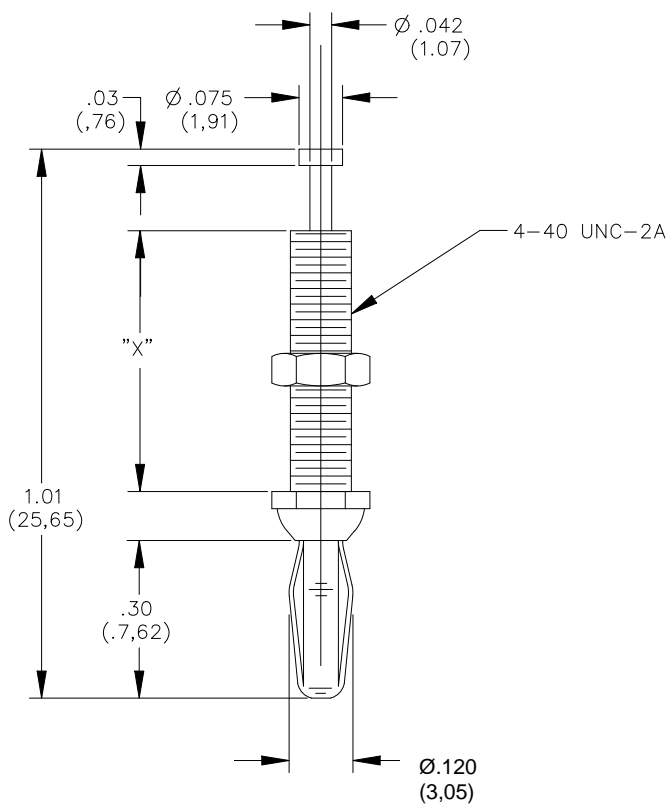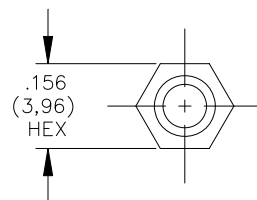

USA: Sales: 800-490-2361
 Technical Support: technicalsupport@pomonatest.com
 Fax: 425-446-5844

Europe: 31-(0) 40 2675 150 **International:** 425-446-5500

Where to Buy: www.pomonaelectronics.com

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Pomona:](#)

[3276](#)