


Model 3302 Shielded Aluminum Box, Size F With BNC Females Both Ends

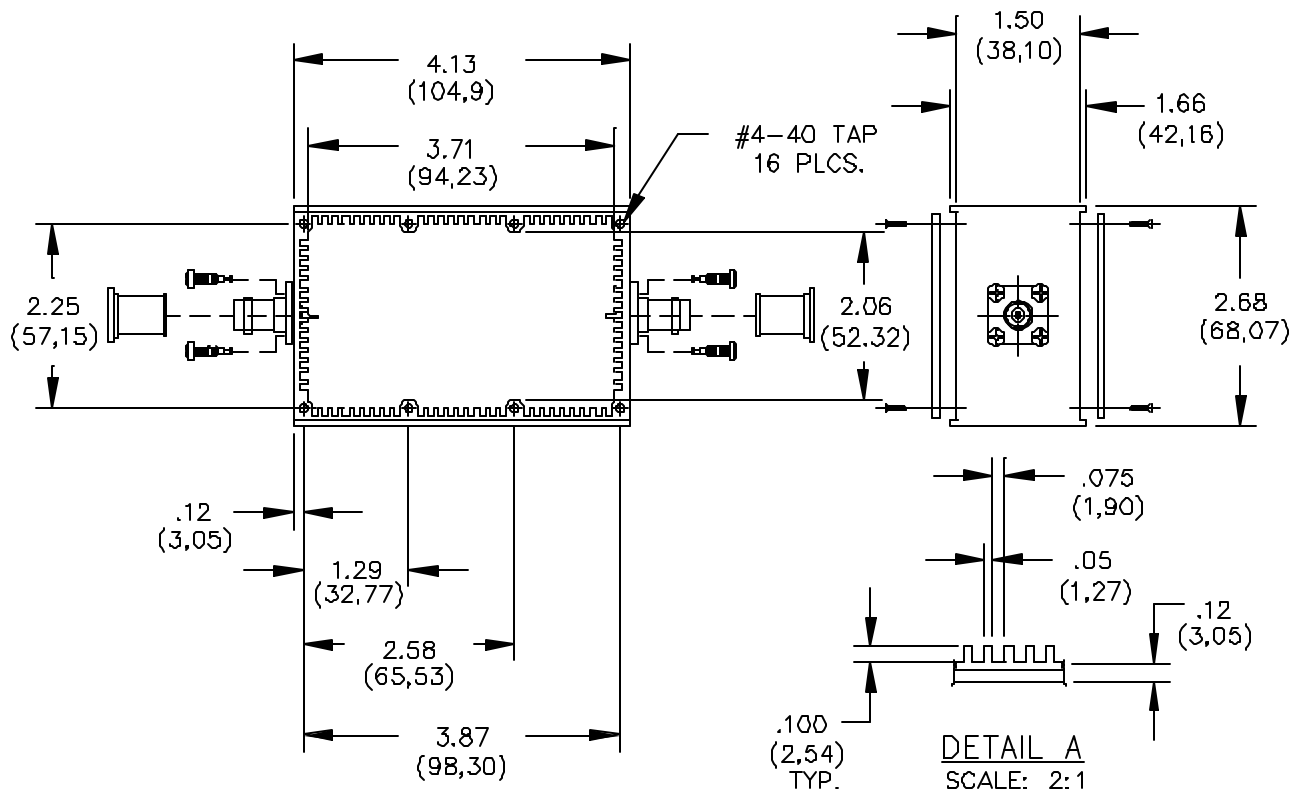

MATERIALS:

Shielded Housing: Extruded Aluminum, Alloy 6063-T5

Finish: Blue paint per Federal Standard 595, #25109 over primer wash per DOD-P-15328

Connector: 2 each BNC Female

Finish: Body and Fittings – Tarnish Resistant. Center Contact – Gold plated

Turret Screws: 4 each #3-30, Steel

Screws: 4 each #4-40 x 6.35 (1/4) per MS 35208-12 with clear irridite dip

Cover: 2 each, 2.03 (.080) thick Aluminum, Alloy #1100-H14

Finish: Clear anodized per MIL-A-8625

Cover Screws: 16 each #4-40 x 6.35 (1/4") Flat head per MS35109-221 with clear irridite dip

RATINGS:

Operating Temperature: -55°C to +150C (-67°F to +302°F)

Nominal Impedance: 50 Ohms

ORDERING INFORMATION: Model 3302

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ± .005" (.127 mm).

All specifications are to the latest revisions. Specifications are subject to change without notice.

Registered trademarks are the property of their respective companies. Made in USA

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Pomona:](#)

[3302](#)