


## Model 3311 Size G Extruded Aluminum Box With Cover

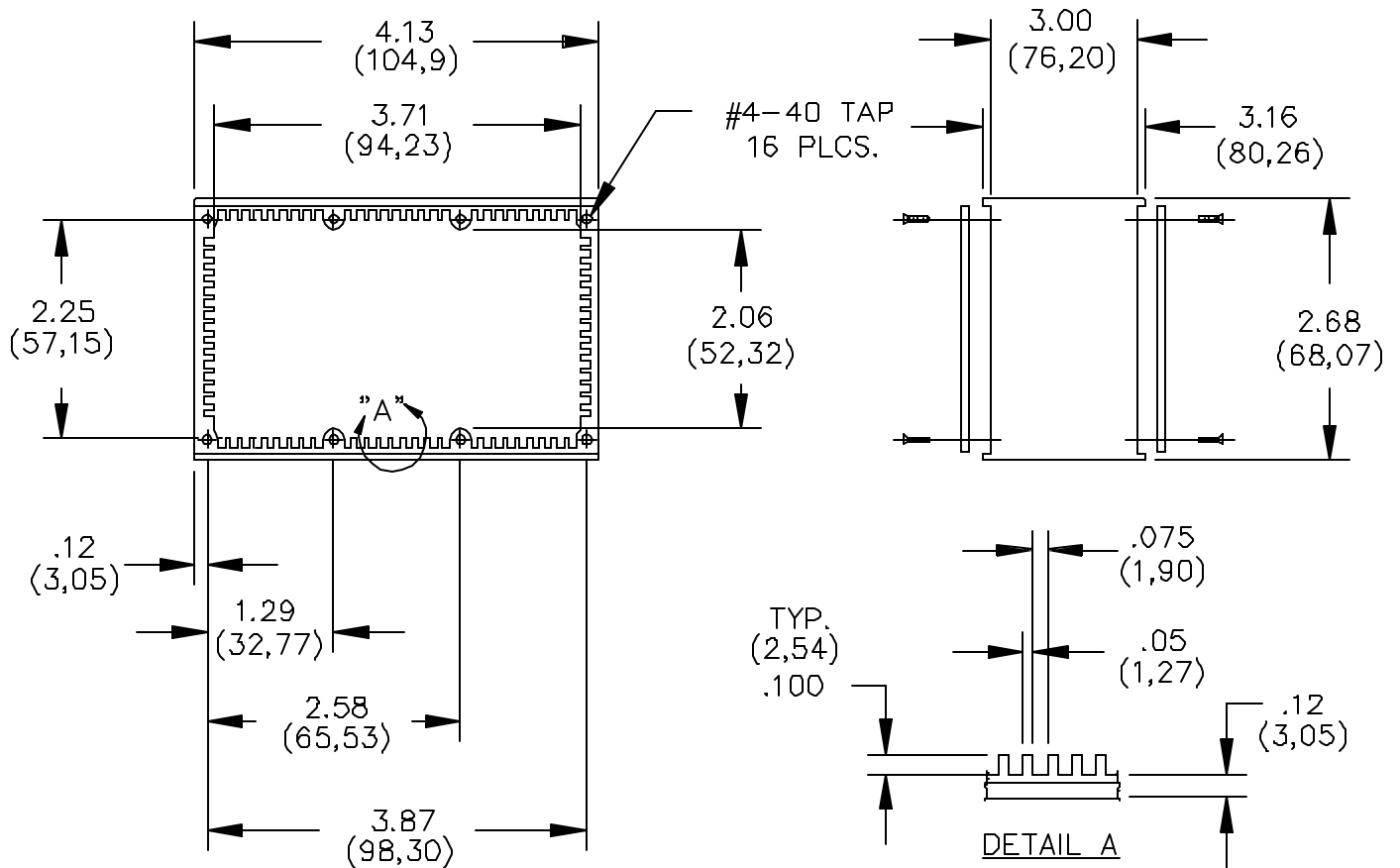

### MATERIALS:

Shielded Housing: Extruded Aluminum, Alloy 6063-ST  
 Finish: Blue baked enamel per Federal Standard 595,  
 #25109 over primer wash per DOD-P-15328.  
 Cover: 2 each, 2.03 (.080) thick Aluminum, Alloy  
 1100-H14

Finish: Clear anodized per MIL-A-8625

Screws: 16 each #4-40 x 6.35 (1/4") Flat head with  
 blue zinc plating

### RATINGS:

Operating Temperature: +150°C (+302°F) Max.

### ORDERING INFORMATION: Model 3311

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm).  
 All specifications are to the latest revisions. Specifications are subject to change without notice.  
 Registered trademarks are the property of their respective companies.

Made in USA

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Pomona:](#)

[3311](#)