


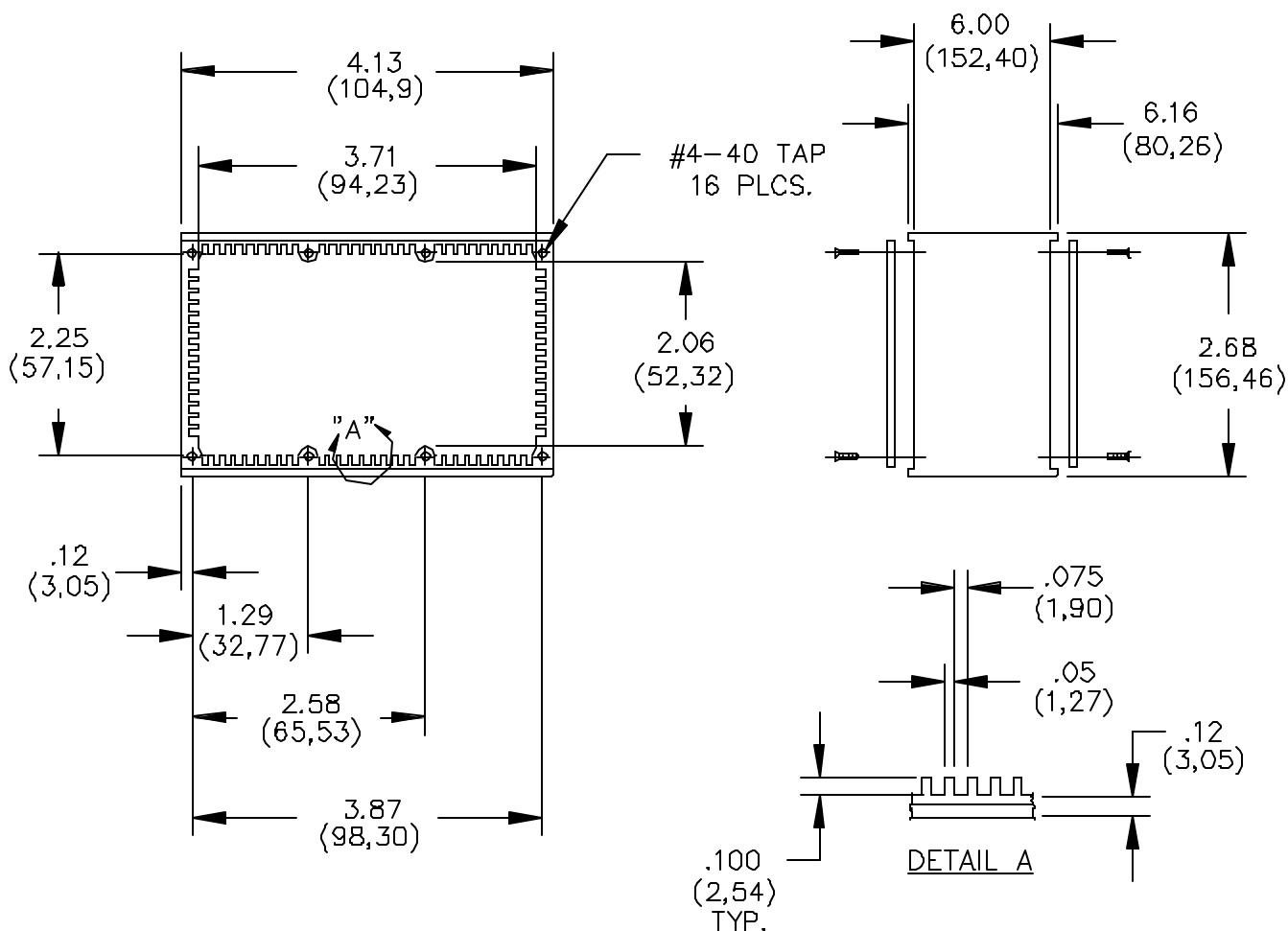

MATERIALS:

Shielded Housing: Extruded Aluminum, Alloy 6063-T5

Finish: Blue baked enamel per Federal Standard 595 #25109 over primer wash per DOD-P-15328

Cover: 2 Each 2.03 (.080) thick aluminum, Alloy 1100-H14

Finish: Clear anodized per MIL-A-8625

Screws: 16 each #4-40 x 6.35 (1/4") Flat head

Finish: Blue zinc plated

RATINGS:

Operating Temperature: +150°C (+302°F) Max.

ORDERING INFORMATION: Model 3742

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm).

All specifications are to the latest revisions. Specifications are subject to change without notice.

Registered trademarks are the property of their respective companies. Made in USA

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

3742