


Model 3786 Minigrabber® Test Clips To Double Banana Plug

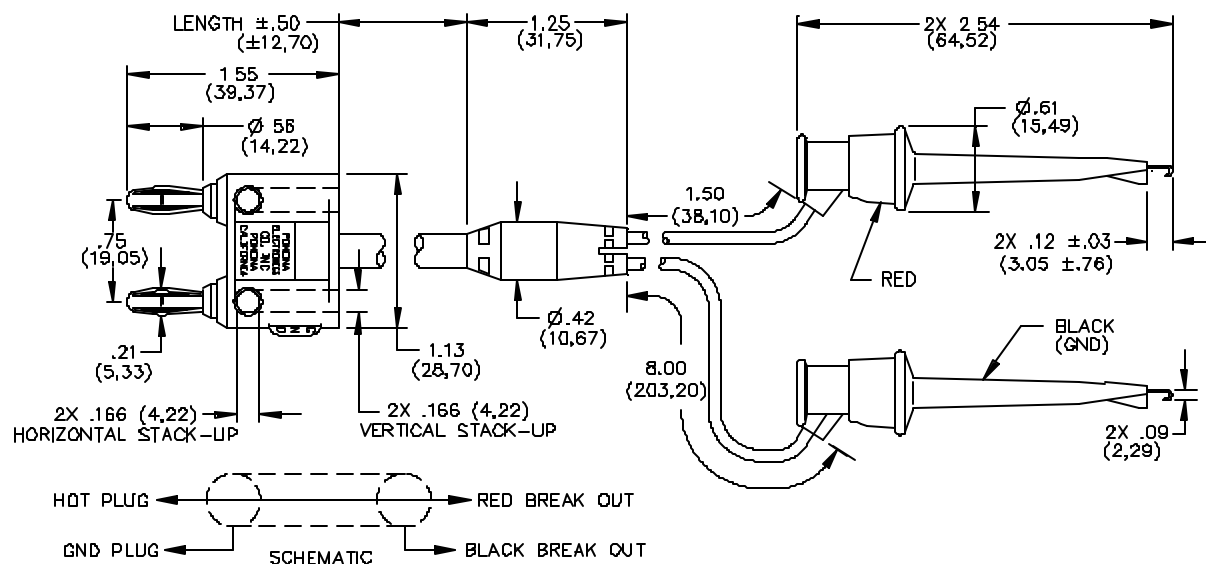

FEATURES:

- Converts double Banana Jacks to Minigrabber Test Clip.
- Lengths other than those specified are available upon request.

MATERIALS:

Conn: 1st End-Double Banana Plug

Material: Spring-Beryllium Copper per QQ-C-533, Alloy 172, Cond. HT.

Plug Body: Brass per QQ-B-626, Alloy 360, 1/2 Hard.

Finish: Nickel plated per QQ-N-290, Class 2, 200/300 microinches.

Insulation: Polypropylene molded to plug bodies and cable. Color matches color of cable.

Marking: "POMONA ELECTRONICS CO., INC. POMONA CALIFORNIA".

Cable: RG58C/U.

Marking: "POMONA 3786-C-XX".

Molded Breakout: PVC molded to breakout leads and cable. Color: Black Breakout Leads: 20 AWG, length.

41 x 36 T.C., PVC insulated, 2.21 (.087) O.D.

One Red Lead, one Black Lead

Conn: 2nd End-Minigrabber®

Material: Contact – Beryllium Copper per QQ-C-533, Alloy 165, 1/4 HM.

Spring: stainless steel, Alloy 302.

Finish: Contact – Gold plated per MIL-G-45204, Type I, Class 00.

Insulation: Glass filled Nylon. Color: One Red and one Black.

Marking: "POMONA ELECTRONICS
"MINIGRABBER®".

RATINGS:

Operating Voltage: 300 VRMS/DC

Operating Temperature: +50°C. (+122°F.) Max

Current: 5 Amperes

ORDERING INFORMATION: Model 3786-C-XX

XX=Cable Length, Standard Length: 18" (457), 24" (610), 36" (914), 48" (1219), 60" (1524)

Ordering Example: Model 3786-C-60 indicates 60" in

All dimensions are in inches. Tolerances (except noted): .xx = $\pm .02$ " (.51 mm), .xxx = $\pm .005$ " (.127 mm).

All specifications are to the latest revisions. Specifications are subject to change without notice.

Registered trademarks are the property of their respective companies. Made in USA

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

[3786-C-48](#) [3786-C-60](#) [3786-C-24](#) [3786-C-18](#) [3786-C-36](#)