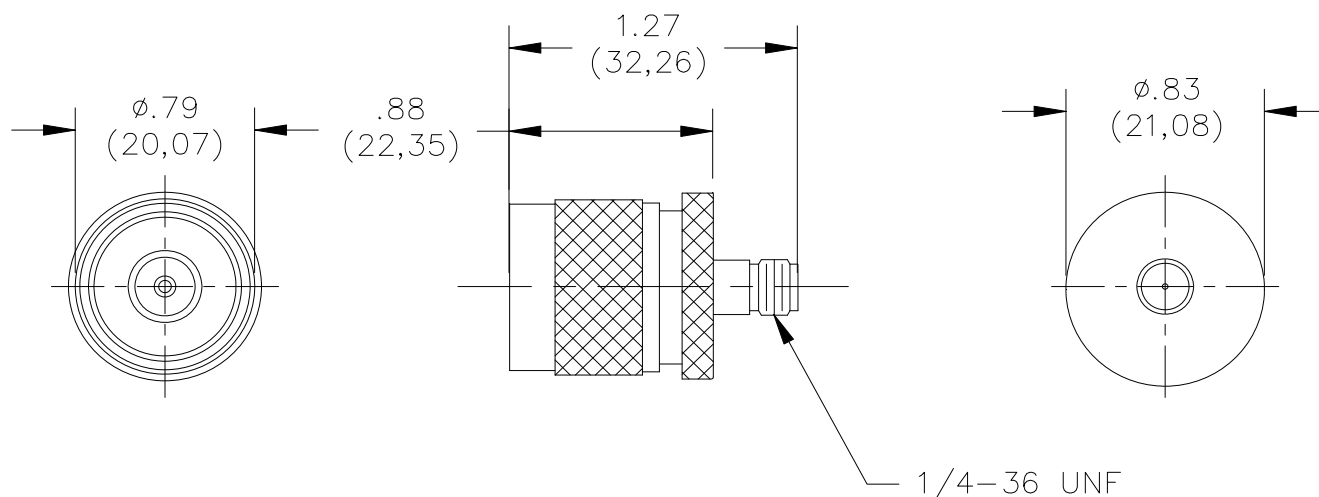


Model 4297
SMA (F) to Type N (M) Adapter**Materials**

Body: Gold Plated Beryllium Copper
Male Contact – Gold Plated Brass
Female Contact – Gold Plated Beryllium Copper
Dielectric: PTFE per L-P-403
Finish: Body and Contacts – Gold Plated per MIL-G-45204, Type II, Class 2
Marking: "Pomona 4297"

Ratings

Operating Voltage:
Shield/Earth: 30VAC/60VDC Max.
Inner Conductor/Shield: 335VRMS Max.
Operating Temperature:
-65°C to +165°C (-85°F to +329°F)
Nominal Impedance: 50 Ohms
Frequency Range: 0 – 12.4 GHz

Ordering Information

Model: 4297

USA: Sales: 800-490-2361
Technical Support: technicalsupport@pomonatest.com
Fax: 425-446-5844
Europe: 31-(0) 40 2675 150 **International:** 425-446-5500
Where to Buy: www.pomonaelectronics.com

All dimensions are in inches. Tolerances (except noted): .xx = $\pm .02$ " (.51 mm), .xxx = $\pm .005$ " (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

4297