


Model 4487 & 5260 BNC (Male) On Retractable Cable With Molded Strain Relief

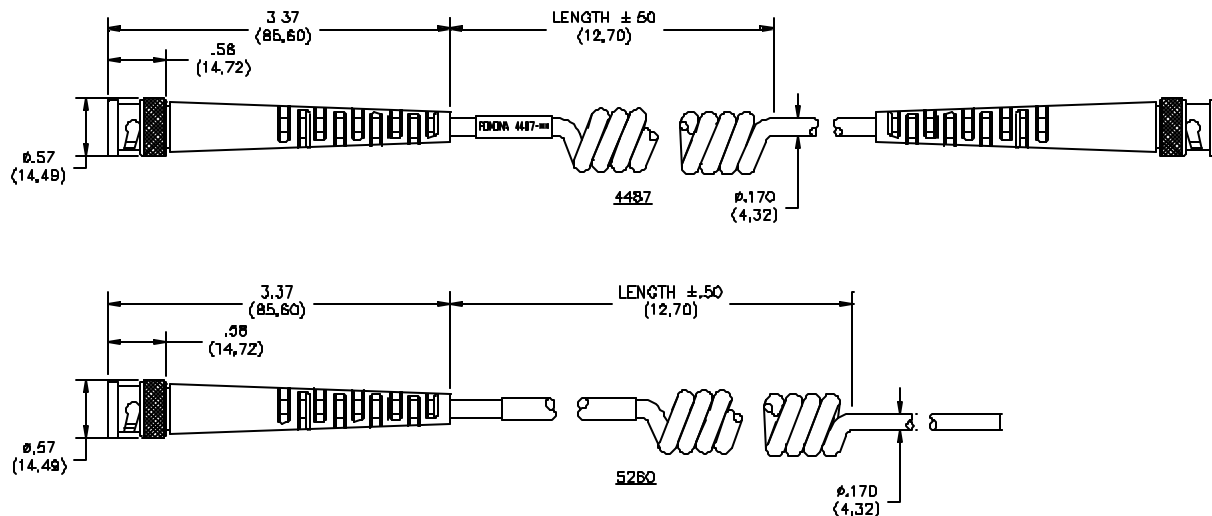

FEATURES:

- BNC center contact is gold plated for optimum electrical connection.
- Flexible Strain Relief is molded to the BNC/Coaxial Cable to ensure long cable life.
- BNC shell is plated for tarnish resistance.

MATERIALS:

BNC (Male): Body: Brass, Nickel Plated

Center Contact: Brass, Gold Plated

Impedance: 50 Ohms

Strain Relief: PVC Molded to Cable, Color: Black

Marking: "POMONA 4487-XX" or "POMONA 5260-XX"

Cable: Shielded microphone, center conductor, 24 AWG (45x40), polyurethane jacket, .170" (4,32 mm).

Pomona part number marked on the cable.

RATINGS:

Operating Temperature: 50°C (+122°F) Max.

Operating Voltage: Shield/Earth: 30VAC/60VDC Max.

Inner Conductor/Shield: 270VRMS Max.

ORDERING INFORMATION: Model 4487-XX (BNC Male, Both Ends) or 5260-XX (BNC Male, One End Only) XX = Extended Length In Inches , Standard. Lengths: 48" (122 cm), 60" (152,4 cm), 72" (183 cm)

Ordering Example: 4487-48 is BNC (Male), Both Ends, Extended Cable Length of 48" (122 cm)

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm).

All specifications are to the latest revisions. Specifications are subject to change without notice.

Registered trademarks are the property of their respective companies.

Made in USA

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

[4487-48](#) [4487-60](#) [4487-72](#)