


Model 4532 Minigator Clips To BNC Male

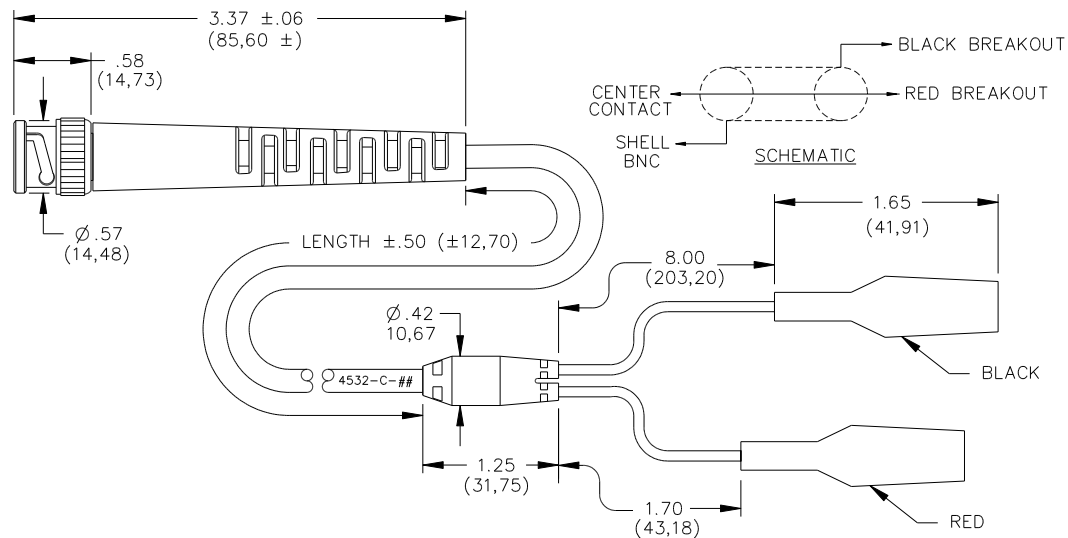

FEATURES:

- Lengths other than those specified are available upon request.

MATERIALS:

Conn: 1st End-BNC Male

Finish: Body and Fittings, Tarnish Resistant.

Nominal Impedance: 50 Ohms.

Center Contact: Gold plated per MIL-C-39012.

Molded Boot: PVC molded to cable and BNC.

Color: Black

Cable: RG58C/U. (.195) O.D.

Marking: "POMONA 4532-C-XX".

Molded Breakout: PVC molded to breakout leads and cable. Color: Black

Breakout leads: 20 AWG; 41 x 36 tinned copper.

PVC insulated 2.21 (.087) O.D.; Color matches

color of insulator. One Red and one Black.

Conn: 2nd End-Insulated Minigator Clips.

Materials: Steel.

Finish: Cadmium plated

Insulators: Vinyl

Colors: Black and Red.

RATINGS:

Operating Temperature: +50°C. (+122°F.) Max.

Operating Voltage: 45 VRMS/DC

Current: 5 Amperes

ORDERING INFORMATION: 4532-C-XX
XX=Cable Length, Standard Lengths: 24" (610),
30" (762), 36" (914), 48" (1219), 60" (1524).
Ordering Example: 4532-C-60 indicates 60" (1524)

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm).

All specifications are to the latest revisions. Specifications are subject to change without notice.

Registered trademarks are the property of their respective companies. Made in USA

6/9/99

Sales: 800-490-2361 Fax: 888-403-3360
Technical Assistance: 800-241-2060

SY/EH/LS

W:\pomona\grponly\Datasheet Updates\Updates 2005\d4532_1_02.doc

More drawings available at www.pomonaelectronics.com

Page 1 of 1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

[4532-C-60](#) [4532-C-30](#) [4532-C-48](#) [4532-C-36](#) [4532-C-24](#)