


Model 4536 Minigrabber® Test Clip, One End With Retractable (Coiled) Cord

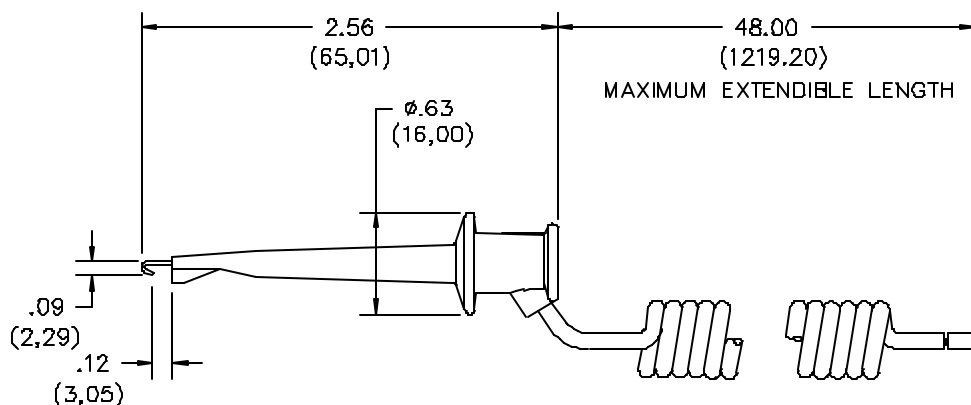

FEATURES:

- Retractable cord to allow connections at various lengths.
- One end open to allow a technician to build a custom load.
- The open end may be used with Model #5169, 5167, 3650, 5173 and various other “Do IT Yourself” Pomona products.

MATERIALS:

Conn: 1st End - Minigrabber® Test Clip

Material: Contact – Beryllium Copper per QQ-C-533, Alloy 165.

Spring – Stainless steel, Alloy 302.

Finish: Contact – Gold plated per MIL-G-45204, Type I, Class 00.

Insulation: Glass filled nylon. Color matches color of wire.

Retractable Cord: 20 AWG, stranding 42 x 36 t.c., PVC insulated, 3.71 (.146) O.D.

Color: See Ordering Information

Marking: “POMONA 4536.”

Conn: 2nd End – None

RATINGS:

Operating Temperature: +60°C. (+140°F.) Max.

Operating Voltage: Hand-Held Testing: 30VAC/60VDC Max.

Current: 5 Amperes

ORDERING INFORMATION: Model 4536-*

*= Color, -0 Black, -2 Red

Ordering Example: 4536-2 Adapter Color is Red

All dimensions are in inches. Tolerances (except noted): .xx = ±.02” (.51 mm), .xxx = ± .005” (.127 mm).

All specifications are to the latest revisions. Specifications are subject to change without notice.

Registered trademarks are the property of their respective companies. Made in USA

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

[4536-2](#) [4536-0](#)