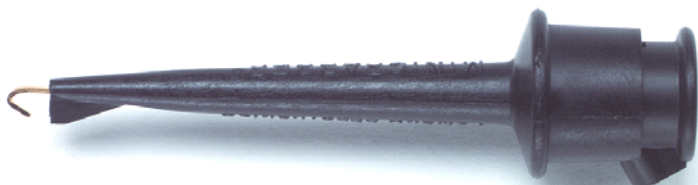
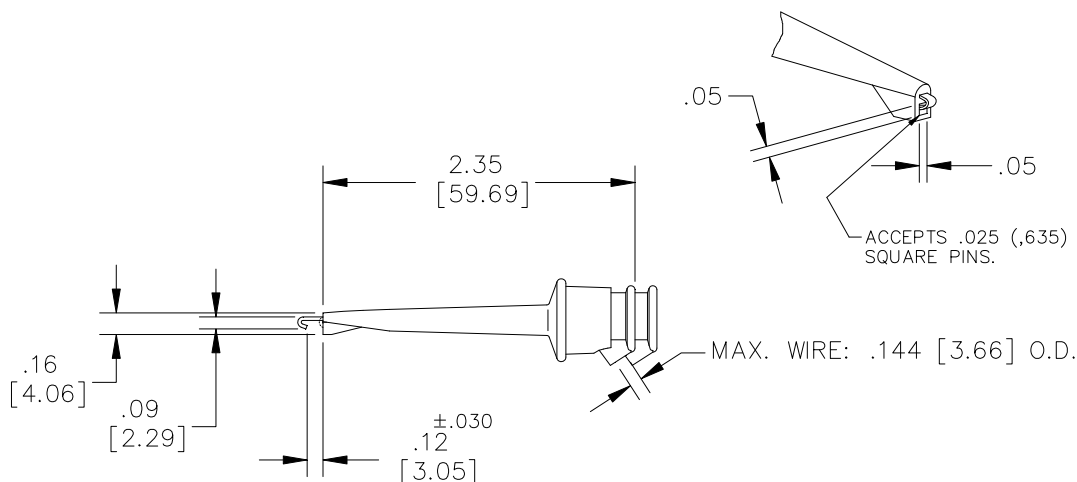


Model 4555
Do-It-Yourself Minigrabber Test Clip

Model 4555
Do-It-Yourself Minigrabber Test Clip

Materials

Contact: Gold Plated Beryllium Copper
Spring: Stainless Steel
Body Insulation: Glass filled nylon

Specifications

Voltage: Maximum voltage for hands free use: 300 Vrms Max.
For CE compliance, do not hold in hand when voltages exceed 30 Vrms / 60 Vdc.
Operating Temperature: +102°C (+216°F) Max.
Current: 5 Amperes

Ordering Information

Model: **4555-***
* = Color: -0 (Black), -2 (Red)
Ordering Example: **4555-2**, Minigrabber is red.

Additional colors may be quoted upon request.
Sold in packages of 10 per color.

USA: Sales: 800-490-2361
Technical Support: technicalsupport@pomonatest.com
Fax: 425-446-5844

Europe: 31-(0) 40 2675 150 **International:** 425-446-5500
Where to Buy: www.pomonaelectronics.com

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm),
.xxx = ±.005" (.127 mm). All specifications are to the latest revisions.
Specifications are subject to change without notice. Registered trademarks are
the property of their respective companies.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

[EM4555-4](#) [EM4555-5](#) [EM4555-6](#) [EM4555-1](#) [EM4555-9](#) [4555-0](#) [4555-2](#) [4555-0#](#) [EM4555-5#](#) [EM4555-6#](#)
[EM4555-4#](#)