


Model 4768 Cable Assembly, Double Banana Plug To Micrograbber® Breakouts

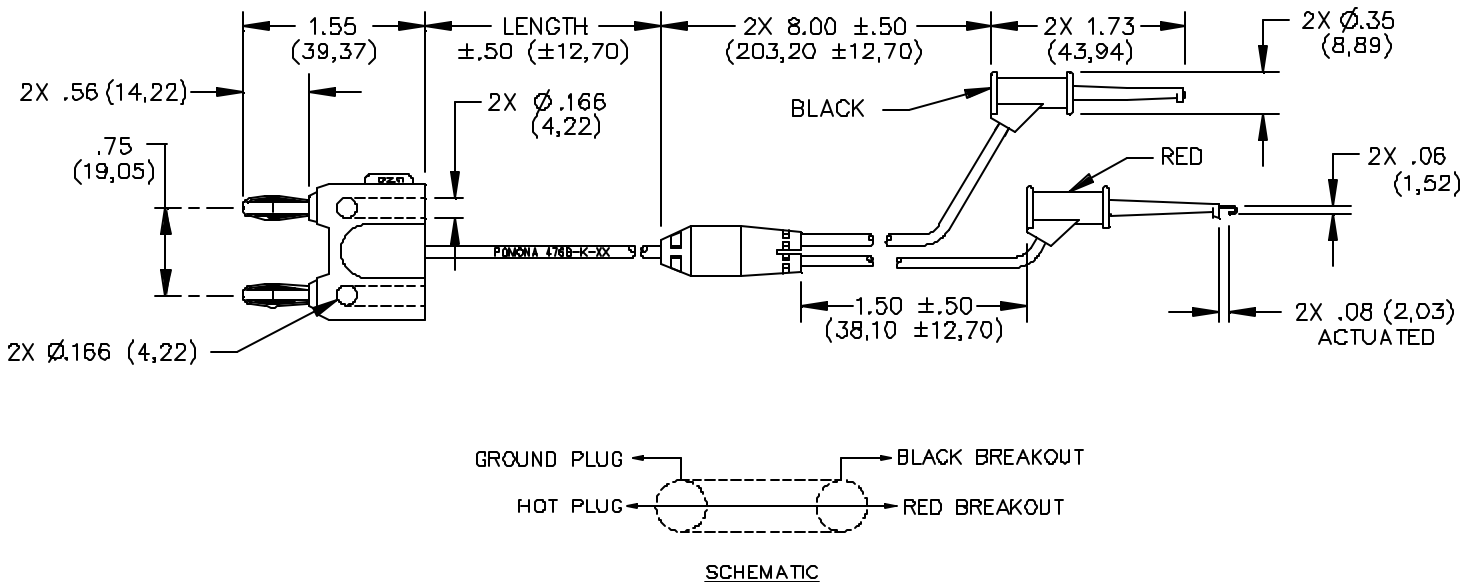

MATERIALS:

Connector: Double Banana Plug

Body: Brass

Spring: Beryllium Copper

Insulation: Polypropylene

Cable: RG 174/U, 2.54 (.100) O.D.

Marking: "Pomona 4768-K-XX"

Molded Breakout: PVC molded to breakout leads and cable.

Wire: 20 AWG

Connector: Micrograbber® Breakouts

Contact – Gold Plated Beryllium Copper

Spring – Stainless steel

Insulation – Glass filled nylon

RATING:

Operating Temperature: +50°C (+122°F) Max.

Operating Voltage: 1000 WVDC

ORDERING INFORMATION: Model 4768-K-XX XX = Cable length

Std. Lengths: 4" (102), 8" (203), 12" (305), 18" (457), 24" (610), 36" (914), 48" (1219), 60" (1524).

Additional lengths can be quoted upon request.

Ordering Example: 4768-K-24 is a cable with a length of 24".

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm).

All specifications are to the latest revisions. Specifications are subject to change without notice.

Registered trademarks are the property of their respective companies. Made in USA

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

[4768-K-48](#) [4768-K-24](#) [4768-K-60](#) [4768-K-36](#)