


Model 4771 Square Pin Receptacle To Banana Plug

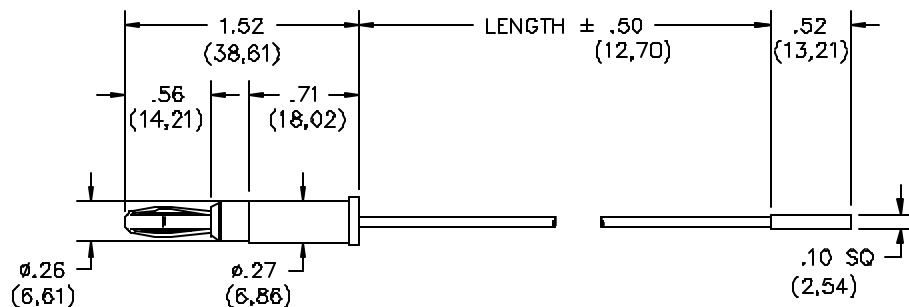

FEATURES:

- This patch cord is excellent for use as a jumper on circuit cards with 0.6 (.025) sq. pins and equipment with 4.2 (.166) dia. pin jacks.
- Mates to Model numbers 5790, 4521, 5360 and 5927.

MATERIALS:

Conn.: In-Line Banana Plug

Material: Spring – Beryllium Copper per QQ-C-533, Alloy 172, Cond. HT. Plug Body – Brass per QQ-B-626, Alloy 360, ½ Hard.

Finish: Nickel plated per QQ-N-290, Class 2, 200/300 microinches.

Insulation: Polypropylene molded to plug body and wire.

Color: Matches color of wire

Wire: 22 AWG, stranding 26 x 36 T.C., PVC Insulated, 1.63 (.064) O.D.

Color: See Ordering Information

Marking: "POMONA 4771-XX"

Conn: 0.64 (.025) Square Pin Receptacle

Material: Phosphor bronze.

Finish: Gold plated.

Housing Insulation: Polypropylene

Color: Matches color of wire.

RATINGS:

Operating Temperature: +50° C. (+122° F.) Max.

Operating Voltage: 1000 VDC

Current: 3 Amperes

ORDERING INFORMATION: Model 4771-XX-*

XX=Cable Lengths, Standard Lengths: 12" (305), 24" (610), 35" (914), & 48" (1219). Additional lengths can be quoted upon request.

*=Color, -0 Black, -2 Red

Ordering Example: 4771-48-2 Indicates 48" in length, color is Red.

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm).

All specifications are to the latest revisions. Specifications are subject to change without notice.

Registered trademarks are the property of their respective companies. Made in USA

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

[4771-12-2](#) [4771-12-0](#) [4771-48-0](#) [4771-48-2](#)