


## Model 5019 & 5019N Cable Assembly - Minigrabber® Test Clips To Bantam Plug

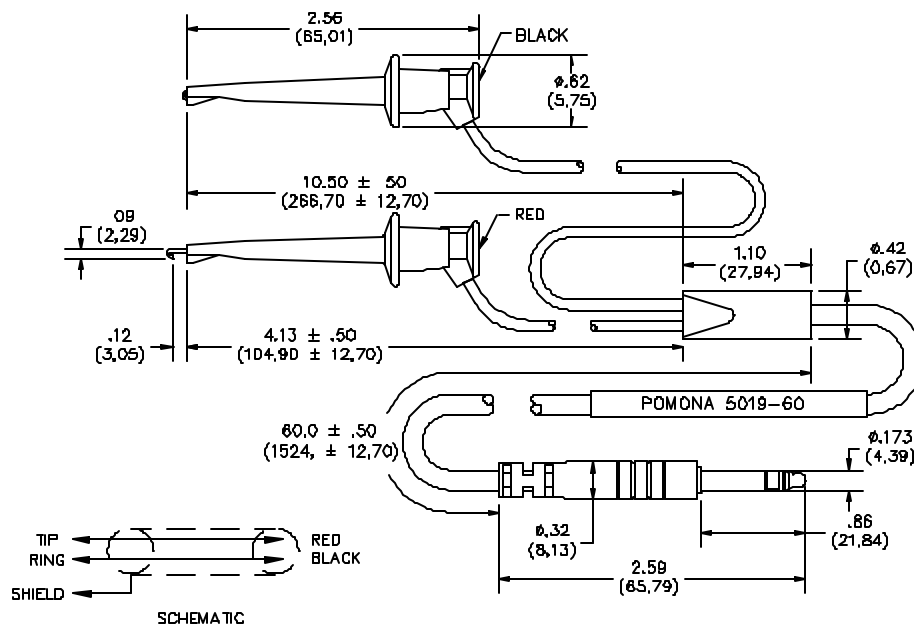

### FEATURES:

- Shielded cable to reduce noise
- Provides quick access from Bantam Jack to terminals
- Bantam Plug is molded to the cable to provide optimum durability

### MATERIALS:

Conn.:

1<sup>st</sup> End - Minigrabber®

Contact – Beryllium Copper

Spring – Stainless Steel

Finish: Contact – Gold Plated

Insulation: Handle – Glass filled nylon.

Color matches wire.

Barrel – Glass filled nylon. Color matches wire.

Marking: “Pomona Electronics”  
“Minigrabber®”

Breakout Leads: 20 AWG, 41 x 36 T.C., PVC insulated, 2.21 (.087) O.D. Color: Red and Black, Red lead connected to tip, Black lead connected to ring.

Molded Breakout: PVC, Color – Gray

Cable: 2 conductor shielded stranded copper, 7 x 30, PVC insulated, 4.57 (.180) O.D. Color – Gray

Conn.:

2<sup>nd</sup> End – Bantam Plug (Miniature Phone Plug)

Finish: 5019 brass, 5019N nickel plated .

Insulation: PVC. Color - Black

### RATINGS:

Operating Temperature: +50°C (+122°F) Max.

Operating Voltage: 300 VRMS/DC

**ORDERING INFORMATION:** Model 5019-60 and 5019N-60

Standard Length – 60” (1520mm)

Ordering Example: 5019N-60, cable is 60” long with brass nickel plated Bantam connector.

All dimensions are in inches. Tolerances (except noted): .xx = ±.02” (.51 mm), .xxx = ± .005” (.127 mm).

All specifications are to the latest revisions. Specifications are subject to change without notice.

Registered trademarks are the property of their respective companies. Made in USA

Sales: 800-490-2361 Fax: 888-403-3360  
Technical Assistance: 800-241-2060

PomonaACCESS 90295 (800) 444-6785 or (425) 446-6010  
More drawings available at [www.pomonaelectronics.com](http://www.pomonaelectronics.com)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

5019N-60 5019-60