 

 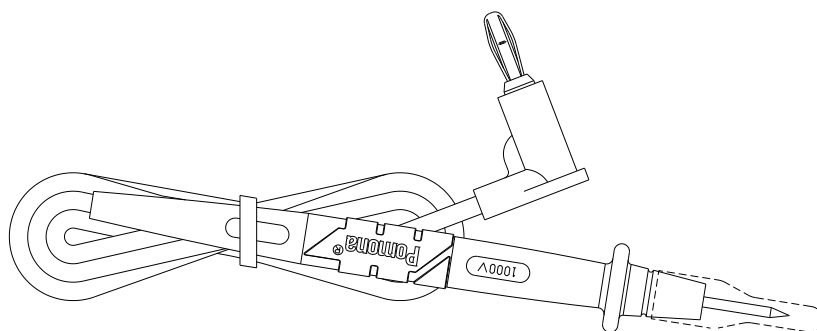


**Model 5672A**  
**Basic Electronic DMM Test Lead Kit**

5682



5916A

(SET BLACK & RED) PROBE TO RIGHT ANGLE

For data sheets / specifications of the kit individual components, visit the Pomona web site at:  
[www.pomonaelectronics.com](http://www.pomonaelectronics.com)

## FEATURES

- Fits Fluke, H-P, Tektronix and Wavetek meters configured with non-sheathed standard and 4 mm banana jacks.
- Test probe body & banana plug body are molded directly to 48" (122 cm), high strand count/high temperature silicone leads for added pull strength and flexibility.
- Wear indication with double insulated (dual extruded) silicone leads shows white inner layer for increased safety.
- Medium alligators are insulated for added safety and can quickly attach to the 0.080" (2.03 mm) O.D. probe tip.
- Medium alligators have an overall length of 2.25" (5.7 cm) and grip up to 0.30" (7.62 mm) O.D. terminals.
- Slide-on extended tips have an overall length of 4" (10.16 cm) & attaches to the probe tip to allow access to hard to reach test points.
- Slide-on Extended Tip is insulated to the point to prevent accidental shorting.

## Kit Accessories

Model **5672A Test Probes**: Test Probes, set of one black and one red.

Model **5682**: Slide-on Extended Tip, set of one black and one red (Replacement P/N: 5682-0/-2).

Model **5916A**: Medium Alligator Clips, set of one black and one red (Replacement P/N: 5916A).

**USA:** Sales: 800-490-2361  
Technical Support: [technicalsupport@pomonatest.com](mailto:technicalsupport@pomonatest.com)  
Fax: 425-446-5844

**Europe:** 31-(0) 40 2675 150 **International:** 425-446-5500

**Where to Buy:** [www.pomonaelectronics.com](http://www.pomonaelectronics.com)

All dimensions are in inches. Tolerances (except noted): .xx =  $\pm 0.02$ " (.51 mm), .xxx =  $\pm 0.005$ " (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.

**Model 5672A**  
**Basic Electronic DMM Test Lead Kit****MATERIALS**

Model: **5672A Test Probes**: Over molded Probe Test Lead w/ right angle banana plugs:

Probe body and banana plug body: Polypropylene – Fire Retardant, Tip: Stainless Steel, Wire: 18 AWG, 192 x 41 bare copper, Silicone Insulation, O.D. 0.144" (3,66mm). Length: 48" (122cm), Banana Plug: Insulation: Polypropylene – Fire Retardant, Plug Body: Brass Nickel Plated, Spring: Beryllium Copper, Nickel Plated,  
**RATINGS**: Operating Voltage: For CE compliance and for personal safety, do not hold in hand when voltages exceed 30 Vrms/42.4 Vpk/60 Vdc or current exceeds 8A maximum. Maximum voltage for hands free use: 1000 V. Do not use on circuits where transient stresses can exceed the rated voltage. Current: 10 Amps.

Model: **5682**: Probe Extended Tip Adapter:

Insulation: Polypropylene, Fire Retardant, Color: one black and one red  
Probe Tip: Stainless Steel with Kynar Insulation Sleeve to Tip End

**RATINGS**: +80°C (+176°F) Max

Model: **5916A**: Medium Alligator Clips:

Insulation: Polypropylene, Fire Retardant, UL94 V-2 Rated, Color: one black and one red  
Body: Steel, Nickel Plated, Spring: Music Wire

**RATINGS**: CAT I 300 V, Current: 5 Amps

**USA:** Sales: 800-490-2361  
Technical Support: [technicalsupport@pomonatest.com](mailto:technicalsupport@pomonatest.com)  
Fax: 425-446-5844

**Europe:** 31-(0) 40 2675 150 **International:** 425-446-5500

**Where to Buy:** [www.pomonaelectronics.com](http://www.pomonaelectronics.com)

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm),  
.xxx = ±.005" (.127 mm). All specifications are to the latest revisions.  
Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Pomona:](#)

[5672A](#)