 
 


**Model 5677B
Deluxe Multi-Use DMM Maxi-Test Lead Kit**




MODEL 5907A
FLEXIBLE TEST LEAD SET WITH RIGHT ANGLE AND STRAIGHT BANANA PLUGS
QTY 2 : 1 RED, 1 BLACK




MODEL 6041B
EXTRA LARGE ALLIGATOR CLIP SET
QTY 2 : 1 RED, 1 BLACK



 MODEL 6252
TEST LEAD COUPLER SET
QTY 2 : 1 RED, 1 BLACK




MODEL 5953A
RETRACTABLE TIP TEST PROBE SET
QTY 2 : 1 RED, 1 BLACK

 

MODEL 6153
SPADE LUG ADAPTER SET
QTY 2




MODEL 5246
IC TEST PROBE TIP ADAPTER SET
QTY 2 : 1 RED, 1 BLACK

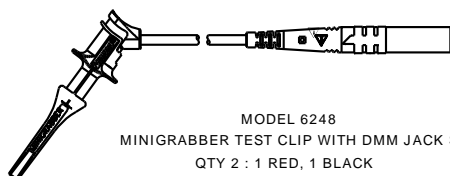


MODEL 6248
MINIGRABBER TEST CLIP WITH DMM JACK SET
QTY 2 : 1 RED, 1 BLACK



 MODEL 6364
0.080 REPLACEMENT PROBE TIP SET
QTY 1 : SET




MODEL 5689A
REPLACEMENT MODULAR TEST PROBE SET
QTY 2 : 1 RED, 1 BLACK

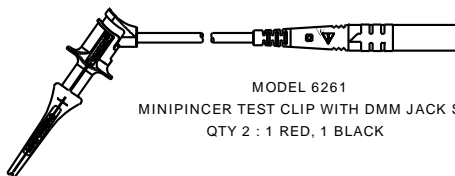

MODEL 6261
MINIPINCER TEST CLIP WITH DMM JACK SET
QTY 2 : 1 RED, 1 BLACK



MODEL 5916A
MEDIUM ALLIGATOR CLIP SET
QTY 2 : 1 RED, 1 BLACK

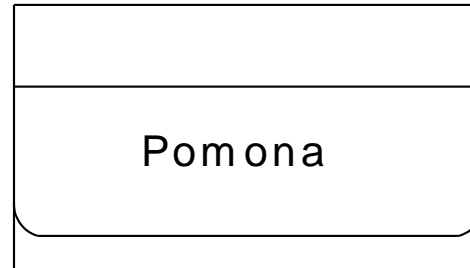

FOUR-FOLD NYLON POUCH

For data sheets / specifications of the kit individual components, visit the Pomona web site at:
www.pomonaelectronics.com

FEATURES:

- Test leads with a right angle banana plug are ideal for use with hand held digital multimeter.
- Flexible test leads feature high strand count silicone wire for extreme flexibility and high temperature resistance.
- Wear indication with double insulated (dual extruded) silicone leads shows white inner layer for increased safety.
- Banana plugs are molded directly to the wire for superior pull strength.
- Retractable needle tip test probe, allowing easy access of hard to reach test points.
- Probes, alligator clips and spade lugs fit directly onto test leads for test versatility.
- Interchangeable test probe tips allows for test versatility from general purpose to SMD applications.
- Test accessories conveniently store in the four-fold nylon pouch.
- Compatible with most multimeters that accept safety style sheath banana plugs.
- CE Compliant; complies with IEC 61010-031 standard for hand held accessories.

USA: Sales: 800-490-2361
Technical Support: technicalsupport@pomonatest.com
Fax: 425-446-5844
Europe: 31-(0) 40 2675 150 **International:** 425-446-5500
Where to Buy: www.pomonaelectronics.com

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Pomona:](#)

[5677B](#)