 
 



Model 5899A
Multi-Use DMM Test Lead Kit


MODEL 6232A
MODULAR PROBE SET WITH BRASS TIP
QTY 2 : 1 RED, 1 BLACK




MODEL 5907A
FLEXIBLE TEST LEAD SET WITH RIGHT ANGLE AND STRAIGHT BANANA PLUGS
QTY 2 : 1 RED, 1 BLACK

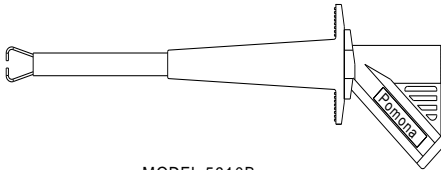

 MODEL 5910B
MAXIGRABBER TEST CLIP SET WITH PINCER TIP
QTY 2 : 1 RED, 1 BLACK



MODEL 5916A
MEDIUM ALLIGATOR CLIP SET
QTY 2 : 1 RED, 1 BLACK

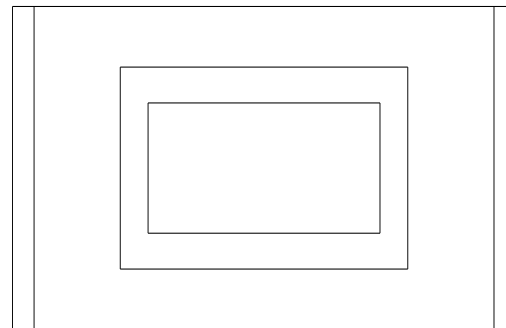

TRI-FOLD NYLON POUCH

For data sheets / specifications of the kit individual components, visit the Pomona web site at:
www.pomonaelectronics.com

FEATURES

- Test leads with a right angle banana plug are ideal for use with hand held digital multimeter.
- Flexible test leads feature high strand count silicone wire for extreme flexibility and high temperature resistance.
- Wear indication with double insulated (dual extruded) silicone leads shows white inner layer for increased safety.
- Banana plugs are molded directly to the wire for superior pull strength.
- Probe body, medium alligator or Maxigrabber Clip® attaches directly to the flexible test leads for test versatility.
- Tri-fold pouch of durable nylon conveniently stores the test accessories.
- Compatible with most multimeters that accepts safety style sheath banana plugs.
- CE Compliant; complies with IEC 61010-031 standard for hand held accessories.



USA: Sales: 800-490-2361
Technical Support: technicalsupport@pomonatest.com
Fax: 425-446-5844
Europe: 31-(0) 40 2675 150 **International:** 425-446-5500
Where to Buy: www.pomonaelectronics.com

All dimensions are in inches. Tolerances (except noted): .xx = ± 0.02 " (.51 mm), .xxx = ± 0.005 " (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

5899A