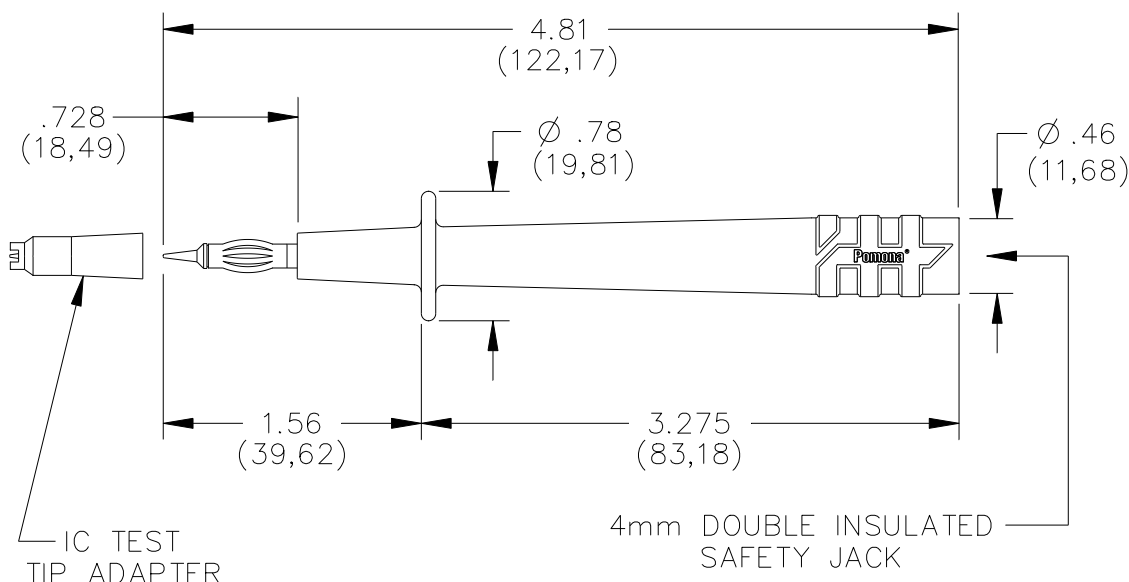


**Model 5906A**  
**Modular Test Probe Handle with Banana Plug Tip****FEATURES**

- Model 5906A has been redesigned to meet IEC 61010-031, which is the latest international safety standard for test accessories.
- Probe safety jack mates to Pomona's 5907A, 5908A and 5909A Flexible Test Leads for digital multimeter interfacing.
- Probe tip cap offers easy DIP lead testing and prevents accidental probe shorting.
- 4 mm banana plug probe tip mates into banana jacks for added test flexibility.

**MATERIAL**

Probe Body: Polypropylene UL94 HB  
Plug Tip: Body – Brass, Nickel Plated  
4mm Safety Jack: Brass, Nickel Plated

**RATINGS**

Operating Voltage: IEC 61010-031, CAT III 1000 V (with protective cap),  
CAT II 1000 V (without protective cap).  
Current: 10 Amperes Max.

**ORDERING INFORMATION**

Model 5906A (Includes a set of one black and one red probe)  
Probe set is also included in many Pomona DMM Test Kits.



**USA:** Sales: 800-490-2361  
Technical Support: [technicalsupport@pomonatest.com](mailto:technicalsupport@pomonatest.com)  
Fax: 425-446-5844  
**Europe:** 31-(0) 40 2675 150 **International:** 425-446-5500  
**Where to Buy:** [www.pomonaelectronics.com](http://www.pomonaelectronics.com)

All dimensions are in inches. Tolerances (except noted): .xx =  $\pm .02$ " (.51 mm),  
.xxx =  $\pm .005$ " (.127 mm). All specifications are to the latest revisions.  
Specifications are subject to change without notice. Registered trademarks are  
the property of their respective companies.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

5906A 5906A#