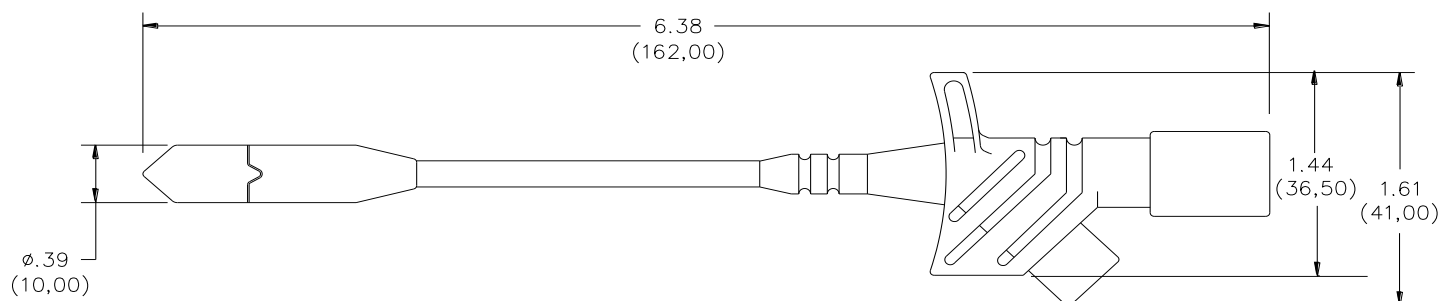


Model 5913
Insulation Piercing Maxigrabber® Test Clip Set**Features**

- Plunger style insulation piercing clip with insulated jaws
- Stainless steel tip pierces insulated wires for otherwise inaccessible test points
- Pierces insulated wire from 24 AWG to 16 AWG wire
- Sheathed 4mm receptacle accepts shrouded banana plugs and unshrouded banana plugs
- Recommended for use with Pomona 5907A, 5908A and 5909A test leads

**Ratings**

Operating Voltage: 1000 Vrms Max.

Do not use on circuits where transient stresses can exceed the rated voltage.

Current: 10 amps

Temperature: -20°C to +55°C (-4°F to +131°F)

Ordering Information

Model **5913** (a set of 1 red and 1 black Maxigrabber® test clips.)

USA: Sales: 800-490-2361
Technical Support: technicalsupport@pomonatest.com
Fax: 425-446-5844

Europe: 31-(0) 40 2675 150 **International:** 425-446-5500

Where to Buy: www.pomonaelectronics.com

All dimensions are in inches. Tolerances (except noted): .xx = ± 0.02 " (.51 mm), .xxx = ± 0.005 " (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

5913