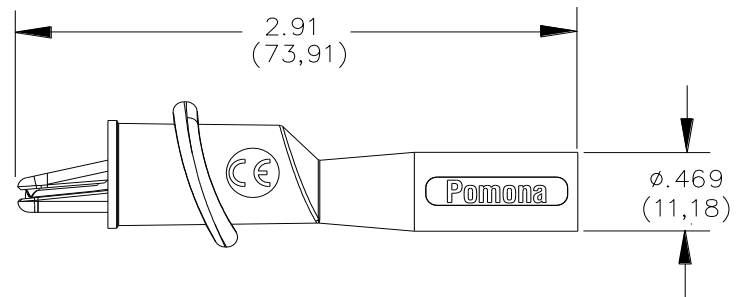
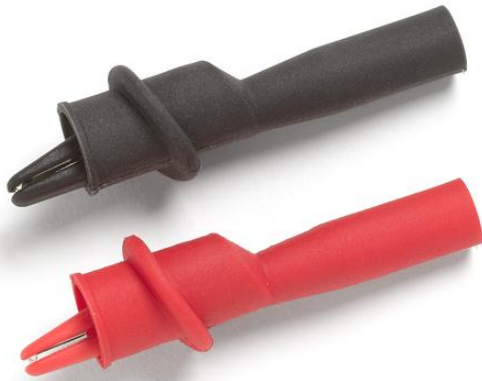


Model 5916B**Medium Alligator Clip with Flex Boot for 4mm Banana Plugs****Features**

- Redesigned to meet IEC 61010-031, the latest international safety standard for test accessories.
- Medium alligator jaw grips onto test terminal up to 0.3" (7.6mm) O.D.
- Flexible thermoplastic boot offers insulation protection.
- Alligator clip features a 4mm sheathed safety jack which interfaces to Pomona's Models 5907A, 5908A and 5909A Flexible Test Leads, or any test leads with 4mm sheathed connectors.

Materials

Alligator Clip:	Steel, nickel-plated
Jaw Insulation:	Polypropylene
Boot:	Santoprene™

Ratings

IEC 61010-031, Pollution Degree 2, 2000 m altitude
Voltage: 1000 V CAT II / 600 V CAT III
Temperature: -20°C to 55°C (-4°F to +131°F) 80% R.H.
Current: 10 amperes max.

Ordering Information

Model: 5916B (Set of one Black, one Red Alligator Clips)
Medium Alligator Clips are also included in many Pomona DMM Test Lead Kits.

USA: Sales: 800-490-2361
Technical Support: technicalsupport@pomonatest.com
Fax: 425-446-5844
Europe: 31-(0) 40 2675 150 **International:** 425-446-5500
Where to Buy: www.pomonaelectronics.com

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

[5916B/POM](#)