


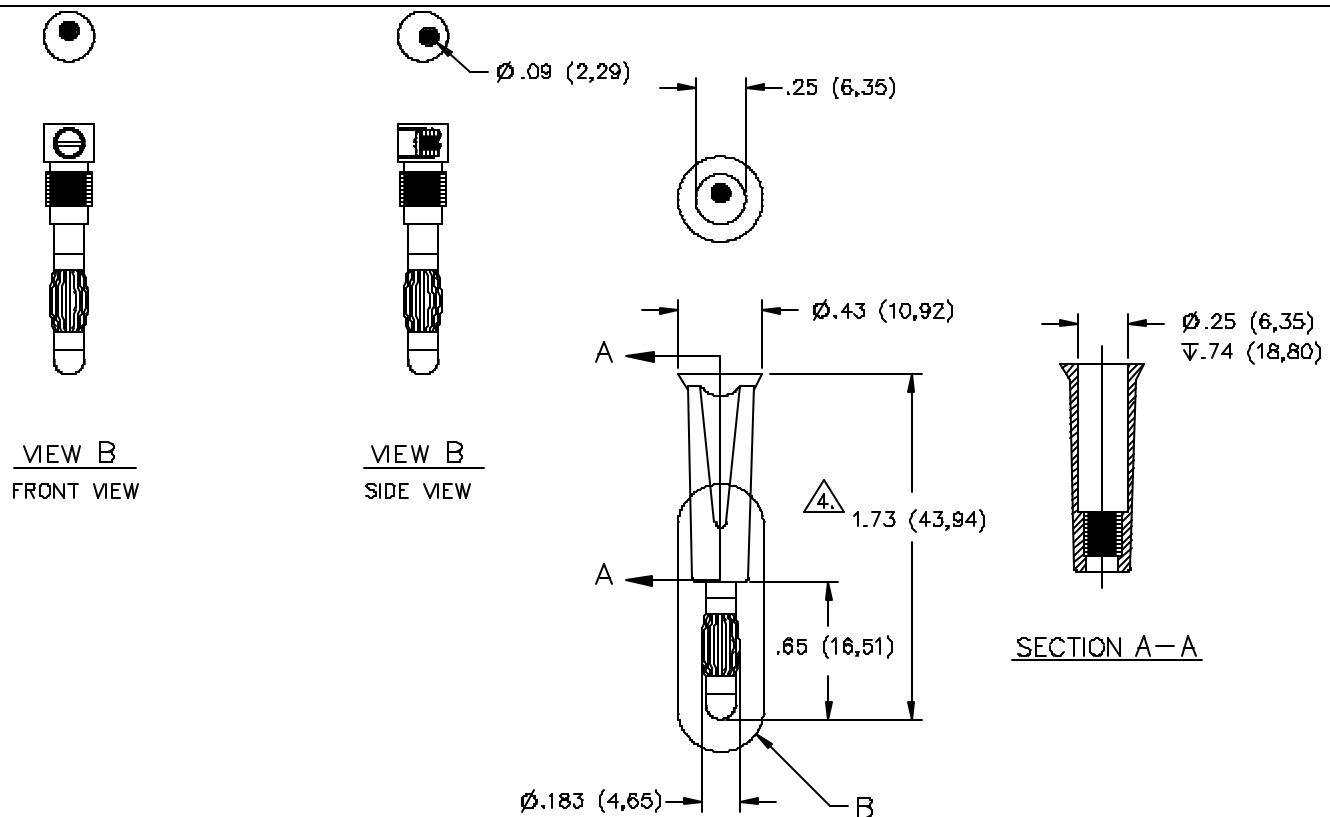

FEATURES:

- Easy to assemble threaded two piece construction enables solderless wire attachment by means of an internal set screw
- Compatible with 18 to 22 AWG wire
- Banana plug spring is Beryllium Copper for long insertion life
- Banana plug body and spring are nickel plated for tarnish resistance

MATERIALS:

Plug Body: Brass, Nickel Plated

Plug Spring: Beryllium Copper, Nickel Plated

Insulation: Nylon

Set Screw: Brass

RATINGS:

Operating Voltage: 750V AC/DC (Independent of Wire)

Current: 25 Amperes Max.

ORDERING INFORMATION: Model 5934-*

Yellow, -5 Green, -6 Blue and -9 White

* = Color Code; Standard Colors: -0 Black, -2 Red, -4

Sold in packages of 10 per color.

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm).

All specifications are to the latest revisions. Specifications are subject to change without notice.

Registered trademarks are the property of their respective companies. Made in USA

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

[5934-5](#) [5934-9](#) [5934-4](#) [5934-6](#)